

开口式固定环

三孔型 / 三螺纹孔型




■三孔型 / 三螺纹孔型




类型		[M] 材质	[S] 表面处理	[A] 附件
三孔型	三螺纹孔型			
SCABAK	SCABAL	一般结构用钢	四氧化三铁保护膜	1个内六角螺栓
SCAEAK	SCAEAL		无电解镀锌	
SCANAK	SCANAL	不锈钢	-	1个内六角螺栓 (不锈钢)

其余 $\sqrt{25}$

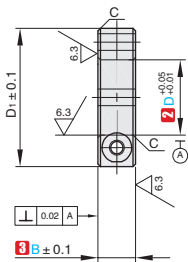

三孔型

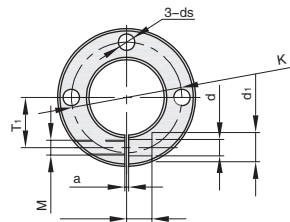

三螺纹孔型

订购编号示例

1 代号 - 2 D - 3 B
 SCABAK - D12 - B10

1 代号	主要尺寸													
	内径 2 D	3 B	D ₁	M(粗牙)	Ms粗牙	d	d ₁	ds	K	a	T ₁	T ₂	C	
(三孔型) SCABAK SCAEAK SCANAK	6	8	20	M3	M3	3.4	6	3.5	12	1.5	1	6	4	0.5
		10		M4		4.5	7.5		13					
	8	8	25	M3	M4	3.4	6	4.5	14		8	5		
		10		M4		4.5	7.5		18					
	10	15	30	M6	M5	6.6	12	5.5	20		9	5		
		8		M3		3.4	6							
		12		M4		4.5	7.5							
	12	15	35	M6	-	6.6	12	6.6	24		10	6		
		8		M3		3.4	6							
		10		M4		4.5	7.5							
	13	12	30	M4	M5	4.5	7.5	5.5	22		10	5		
		10		M3		3.4	6							
15		M5		5.5		9								
15	15	35	M6	-	6.6	12	6.6	24	11	6				
	10		M4		4.5	7.5								
	12		M5		5.5	9								
16	15	40	M6	M5	6.6	12	6.6	28	11	8				
	10		M4		4.5	7.5								
	12		M5		5.5	9								
20	15	40	M6	M5	6.6	12	6.6	28	10	6				
	10		M4		4.5	7.5								
	12		M5		5.5	9								
25	15	45	M6	M6	6.6	12	6.6	34	12	6				
	10		M4		4.5	7.5								
	12		M5		5.5	9								
30	15	50	M6	M6	6.6	12	6.6	38	12	6				
	10		M4		4.5	7.5								
	12		M5		5.5	9								
35	15	60	M6	M6	6.6	12	6.6	44	13	7				
	10		M4		4.5	7.5								
	12		M5		5.5	9								
40	15	70	M8	M8	9	14	9	56	14	7				
	10		M4		4.5	7.5								
	12		M5		5.5	9								
50	15	85	M10	-	11	18	11	68	15	8				
	10		M4		4.5	7.5								
	12		M5		5.5	9								

A3
固定环