

 
压轧滚珠丝杠螺帽支架 专用型



■ 专用型

NEW
新产品

CAD
2D/3D




① 代号 (通用型)	④ 材质	⑤ 表面处理
BNSBBZ	S45C	发黑
BNSBNZ		无电解镀锌
BNSAYZ	A5052	本色阳极氧化

B5
滚珠丝杠
支架组件

订购编号示例

① 代号	-	② 规格	-	③ H
BNSBBZ	-	1002	-	17

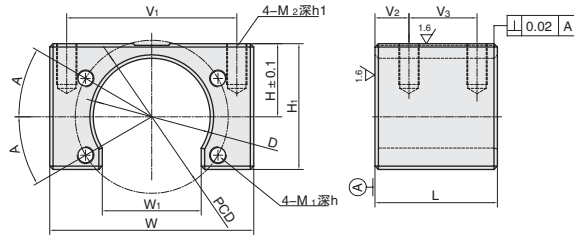

型号		③ H 选择	W	H ₁	P.C.D	A	M ₁ xh	D	V ₁	W ₁	L	V ₂	V ₃	M ₂ xh ₁	适用滚珠丝杠 (C7) (C10)	
① 代号	② 规格														丝杠 轴径	丝杠 导程
802	17 20 23 25		40	H+13	23		M3x6	16.4	30	12						8
1002	17 20 23 25 28 30 35		43	H+15	27		M4x8	18.4	34	16	24	6	12	M4x8		2
1004	25 28 30 35 40			H+14	36	30	M4x8	26.4		22	36	10	16			10
1204	25 28 30 35 40		52	H+17	39		M5x8	28.4	42		20	27	6	15	M5x10	4
1210	25 28 30 35 40		60	H+16	32	45	M4x8	24.4	50	12	40	10	20			12
1520	28 30 35 40			H+17	45	30	M5x10	34.4		28	50		30			15
1605	28 30 35 40			H+20	38	45	M5x8	28.4	52		36	8		M6x12		5
1610	28 30 35 40		62	H+20	38	45	M5x8	28.4	52	12	42	11	20			16
BNSBBZ																
BNSBNZ																
BNSAYZ																
2005	35 40 45		76	H+22					64							5
2010	35 40 45 55		82	H+23	47	45	M6x10	36.4	70		55	10	35			20
2020	35 40 45		68	H+21	50	30	M5x7	39.4	56		70	15	40	M8x16		20
2505	40 45 55		76						64		40		20			5
2510	40 45 55			H+24	51	45	M6x10	40.4			55		35	M10x20		10
2525	40 45 55		82	H+25	60	30		47.4	70	25	90	10	70	M8x16		25
3210	45 55		116	H+31	65	45		50.4	96		80		60	M10x20		10
3232	45 55		106	H+30	74	30	M8x12	58.4	86		75		55	M10x20	32	32



小单	中大单	大单
1-50	51-100	101-
通常	7 工作日	现询



1-9	10~
100%	现询