

# 弹簧垫圈

## 标准型




■标准型



①代号	类型	M 材质	S 表面处理
WRBD	标准型弹簧垫圈	65Mn( 弹簧钢 )	镀锌
WRBA			发黑
WRBB		SUS304	—
WRBE		SUS316	

▲适用标准: DIN 127B。

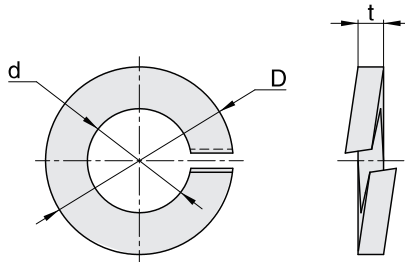

订购编号示例

①代号	-	②公称直径
WRBD	-	D5

型号		d	D	t
①代号	②公称直径			
WRBD WRBA	3	3.1	5.2	0.7
	4	4.4	6.8	1.2
	5	5.4	8.2	1.4
	6	6.68	10.08	1.7
	8	8.68	13.08	2.2
	10	10.9	16.4	2.75
	12	12.9	19.4	3.25
	14	14.9	22.5	3.8
	16	16.9	25.5	4.3
	18	19.04	28.44	4.7
	20	21.04	31.44	5.2
	22	23.34	34.74	5.7
	24	25.5	37.9	6.2
	27	28.5	42.7	7.1
30	31.5	47.1	7.8	

型号		d	D	t
①代号	②公称直径			
WRBB WRBE	1.6	1.8	3.4	0.8
	2	2.35	3.51	0.58
	2.5	2.85	4.31	0.73
	3	3.4	5.2	0.9
	4	4.4	6.8	1.2
	5	5.4	8.2	1.4
	6	6.68	10.08	1.7
	8	8.68	13.08	2.2
	10	10.9	16.4	2.75
	12	12.9	19.4	3.25
	14	14.9	22.5	3.8
	16	16.9	25.5	4.3
	18	19.04	28.44	4.7
	20	21.04	31.44	5.2
	22	23.34	34.74	5.7
	24	25.5	37.9	6.2
	27	28.5	42.7	7.1
	30	31.5	47.1	7.8
33	34.7	52.3	8.8	
36	37.7	56.3	9.3	

F6  
垫片/吊环  
螺丝/螺母