

内六角紧定螺钉

平端




■平端



①代号 平端	[M] 材质	[H] 硬度	[S] 表面处理
SYLADG	SCM435	45HRC-	发黑
SYLBDG	SUS304	-	-

产品特点: 适用于传递载荷较大场合的紧固。

▲适用于标准: GB/T 77-2000
▲相当 DIN913

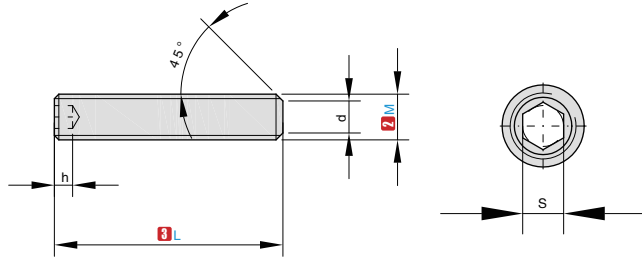

订购编号示例

①代号	-	② M	-	③ L
SYLADG	-	M5	-	L10

型号		③ L														S	h	d	
①代号	② M																		
(碳钢) SYLADG	2	2	3	4	5											0.9	0.8	1	
	2.5	3	4	5	6	8											1.3	1.2	1.5
	3	3	4	5	6	8	10	12	16	20						1.5	1.2	2	
	4	3	4	5	6	8	10	12	16	20						2	1.5	2.5	
	5	4	5	6	8	10	12	16	20	25	30					2.5	2	3.5	
	6	5	6	8	10	12	16	20	25	30	35	40	45	50	3	2	4		
	8	6	8	10	12	16	20	25	30	35	40	45	50	4	3	5.5			
	10	8	10	12	16	20	25	30	35	40	45	50	5	4	7				
	12	10	12	16	20	25	30	35	40	45	50	60	70	6	4.8	8			
	16	16	20	25	30	35	40	45	50	60	70	8	6.4	12					

型号		③ L														S	h	d	
①代号	② M																		
(不锈钢) SYLBDG	2	2	3	4	5	6	8	10	12							0.8	0.8	1	
	2.5	2.5	3	4	5	6	8	10	12							1.2	1.2	1	
	3	3	4	5	6	8	10	12	16	20	25					1.5	1.2	2	
	4	3	4	5	6	8	10	12	16	20	25	30	35	40	50	2	1.5	2.5	
	5	3	4	5	6	8	10	12	14	16	20	25	30	35	40	50	2.5	2	3.5
	6	4	5	6	8	10	12	16	20	25	30	35	40	50	3	2	4		
	8	5	6	8	10	12	16	20	25	30	35	40	50	60	4	3	5.5		
	10	6	8	10	12	16	20	25	30	35	40	50	55	60	5	4	7		
	12	8	10	12	16	20	25	30	35	40	50	55	6	4.8	8				
	16	12	16	20	25	30	35	40	50	8	6.4	12							

F6
垫片/吊环
螺母