

# 梯形齿橡胶带

## XL 型

**成本**  
经济型产品

**交期缩短**

**大批量订购**  
bulk order


XL 型



型式	齿面保护层	材质	芯线
ABRN-XL	尼龙帆布	氯丁橡胶	玻璃纤维

产品特点: 该产品规格广泛应用于安防、玻璃陶瓷、建材木业、金属塑胶、印刷丝印、包装纺织、食品饮料、烟草、仪器仪表、电线电缆、电子电器、汽车、体育运动等行业的工控机械设备传动。

注: 使用温度 -20~80°C。

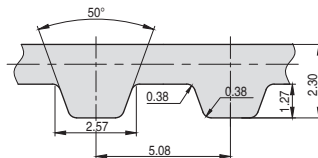

ABRN-XL  
XL型

**订购编号示例**

① 代号	-	② 齿形	③ 公称宽度	-	④ 编号
ABRN	-	XL	025	-	50

ABRN-XL (齿距: 5.08mm)					
① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数
ABRN	XL	025 (6.4mm)	34	172.72	34
			35	177.8	35
			42	213.36	42
			44	223.52	44
			45	228.6	45
			48	243.84	48
			49	248.92	49
			50	254	50
			51	259.08	51
			52	264.16	52
		54	274.32	54	
		55	279.4	55	
		56	284.48	56	
		57	289.56	57	
		58	294.64	58	
		59	299.72	59	
		60	304.8	60	
		61	309.88	61	
		62	314.96	62	
		63	320.04	63	
		64	325.12	64	
		65	330.2	65	
		67	340.36	67	
		68	345.44	68	
		69	350.52	69	
		70	355.6	70	
		71	360.68	71	
		72	365.76	72	
		73	370.84	73	
		74	375.92	74	
		75	381	75	
		77	391.16	77	
		78	396.24	78	
		79	401.32	79	
80	406.4	80			
81	411.48	81			
82	416.56	82			
83	421.64	83			
84	426.72	84			
85	431.8	85			
87	441.96	87			
88	447.04	88			
89	452.12	89			

ABRN-XL (齿距: 5.08mm)					
① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数
ABRN	XL	025 (6.4mm)	90	457.2	90
			91	462.28	91
			95	482.6	95
			97	492.76	97
			98	497.84	98
			99	502.92	99
			100	508	100
			101	513.08	101
			103	523.24	103
			105	533.4	105
		106	538.48	106	
		110	558.8	110	
		114	579.12	114	
		115	584.2	115	
		117	594.36	117	
		120	609.6	120	
		125	635	125	
		130	660.4	130	
		135	685.8	135	
		138	701.04	138	
		141	716.28	141	
		145	736.6	145	
		150	762	150	
		155	787.4	155	
		157	797.56	157	
		170	863.6	170	
		174	883.92	174	
		176	894.08	176	
		180	914.4	180	
		188	955.04	188	
		192	975.36	192	
		195	990.6	195	
		198	1005.84	198	
		212	1076.96	212	
230	1168.4	230			
245	1244.6	245			
282	1432.56	282			
296	1503.68	296			
315	1600.2	315			
414	2103.12	414			
430	2184.4	430			

G5  
拉手/合页  
手柄/手轮  
门组件