


中轻载型支脚

★ 产品特点：底座由增强尼龙（PA6）制成，耐撞击和敲打，耐腐蚀；底部搭配橡胶垫，可起到一定防滑效果；螺杆与底座可进行转动，用于不平衡地面；螺杆高度可通过一体六方调节；

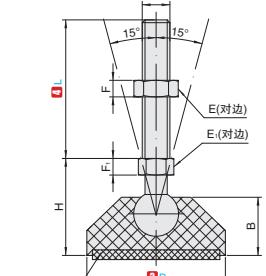

①代号	底盘		螺杆	
	M 材质	S 表面处理	M 材质	S 表面处理
SFBCAWB	增强尼龙(PA6)		45#	镀铬
SFSAW			SUS304	无

视角标准：第一视角



①代号 - ②底径 - ③螺纹直径 - ④螺纹长度
SFBCAWB - D30 - M10 - L100

订购编号示例

型号		主要尺寸							承载	参考重量(kg/pcs)	
①代号	②D	③M	④L	E	E ₁	H	B	F ₁	F	45#	SUS304
钢 SFBCAWB	30	M8	50	14				6.5	6.5	0.02	0.05
		100								0.04	0.04
		M10	50	17				8	8	0.04	0.04
		100								0.06	0.06
		M12	50	19				10	10	0.04	0.04
		100								0.06	0.06
		M12	100							0.08	0.08
		M14	50							0.05	0.05
		100								0.07	0.07
		M14	100							0.07	0.07
不锈钢 SFSAW	40	M8	50	14				6.5	6.5	0.09	0.11
		100								0.10	0.13
		M10	50	17				8	8	0.09	0.11
		100								0.10	0.13
		M12	50	19				10	10	0.07	0.07
		100								0.08	0.11
		M12	100							0.12	0.18
		M14	50							0.14	0.20
		100								0.10	0.12
		M14	100							0.14	0.16
50	50	M8	50	14				6.5	6.5	0.08	0.08
		100								0.10	0.10
		M10	50	17				8	8	0.08	0.10
		100								0.10	0.11
		M12	50	19				10	10	0.08	0.07
		100								0.10	0.11
		M12	100							0.13	0.15
		M16	50							0.21	0.22
		100								0.17	0.08
		M16	100							0.22	0.11
60	60	M10	50	17				8	8	0.16	0.15
		100						10	10	0.12	0.11
		M12	50	19				8	8	0.15	0.16
		100								0.18	0.19
		M12	100					11	11	0.14	0.13
		M14	50	22						0.20	0.10
		100								0.21	0.17
		M14	100							0.21	0.17
		M16	50					13	13	0.3	0.30
		100								0.3	0.30
80	80	M10	50	17				8	8	0.21	0.13
		100						10	10	0.14	0.13
		M12	50	19				11	11	0.16	0.19
		100								0.20	0.10
		M16	50	24				13	13	0.21	0.17
		100								0.21	0.17
		M20	50	30				15	15	0.3	0.30
		100								0.25	0.16
100	100	M16	50	24				16	16	0.37	0.32
		100								0.47	0.48
		M20	50	36				13	13	0.19	0.19
		100								0.21	0.21
150	150	M16	50	24				16	16	0.23	0.23
		100								0.29	0.29
150	150	M20	50	36				19	19	0.33	0.33
		100								0.33	0.33



数量分类	小单	中大单	大单
数量	1~50	51~100	101~



数量	1~9	10~
价格	100%	另行报价

