


精密支脚



★ 产品特点: 超重载型, 精密。



①代号	底盘		螺杆		橡胶垫
	④材质	④材质	⑤表面处理		
SFSHW	SUS304	SUS304	无		丁腈橡胶(NBR)

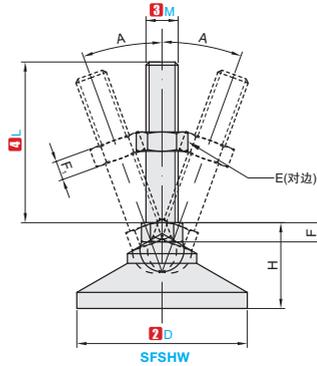

①代号 - ②底径 - ③螺纹直径 - ④螺纹长度
 SFSHW - D80 - M20 - L100

型号		③M	④L	H	E	F	F ₁	A	承载(Kg)	参考重量 (Kg/pcs)
①代号	②D									
不锈钢 SFSHW	80	20	100	58	30	13	16	20°	1500	0.98
			150							1.08
		24	150	61	36	16	19	2000	1.18	
			200						1.3	
			200						1.46	

▲ 承载与参考重量仅供参考。

▲ 螺杆倾斜角度请勿超过图纸参数, 防止出现螺杆与底盘脱落。



数量分类	小单	中大单	大单
数量	1-50	51-100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	另行报价

G2
支脚

