

**Nr. 6848GH**
**Gegenhalter**

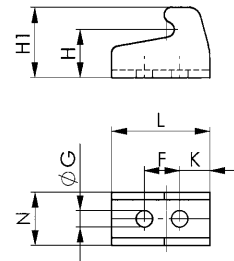
 für Nr. 6848H.  
 Verzinkt und passiviert.

Bestell-Nr.	Größe	F	ØG	H	H1	K	L	N	Gewicht [g]	€/St.	€/St.
										ab 1	ab 10
94821	2	11	5,2	12	18	8	26	18	16	6,25	5,70
94839	3	14	6,5	19	28	12	39	23	44	7,05	6,55
94847	4	19	8,5	26	38	17	56	30	108	8,35	7,45


**Nr. 6848GHNI**
**Gegenhalter**

 für Nr. 6848HNI.  
 Nicht rostender Stahl, poliert.


Bestell-Nr.	Größe	F	ØG	H	H1	K	L	N	Gewicht [g]	€/St.	€/St.
										ab 1	ab 10
95638	2	11	5,2	12	18	8	26	18	16	9,75	9,00
95646	3	14	6,5	19	28	12	39	23	44	10,90	9,75
95653	4	19	8,5	26	38	17	56	30	108	14,10	12,80


**Nr. 6848GV**
**Gegenhalter**

 für Nr. 6848V.  
 Verzinkt und passiviert.

Bestell-Nr.	Größe	F	ØG	H	H1	K	L	N	Gewicht [g]	€/St.	€/St.
										ab 1	ab 10
94854	2	11	5,2	5	12	5	26	18	14	6,25	5,70
94862	3	14	6,5	6	16	7	36	23	30	7,05	6,55
94870	4	19	8,5	8	22	9	48	30	66	8,35	7,45


**Nr. 6848GVNI**
**Gegenhalter**

 für Nr. 6848VNI.  
 Nicht rostender Stahl, poliert.


Bestell-Nr.	Größe	F	ØG	H	H1	K	L	N	Gewicht [g]	€/St.	€/St.
										ab 1	ab 10
95661	2	11	5,2	5	12	5	26	18	14	9,75	9,00
95679	3	14	6,5	6	16	7	36	23	30	11,10	10,00
95687	4	19	8,5	8	22	9	48	30	66	13,70	12,50

