



**Pg gerade Kabel-Schlauch-Verschraubung, Aussen-  
gewinde, Messing-vernickelt.**

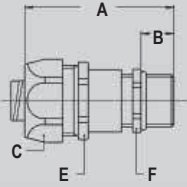


Gewinde	Sealtite	Klemm- bereich (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	E	F			
Pg 9	5/16"	4 - 8	55	10	26	24	17	25	810.709.1	7,8
Pg 9	3/8"	5 - 8	55	10	26	24	20	25	810.712.1	7,8
Pg 11	3/8"	5 - 10	55	10	26	24	20	25	810.711.1	9,5
Pg 13,5	1/2"	6 - 12	57	10	29	27	22	25	810.715.1	9,7
Pg 16	1/2"	10 - 13,9	60	10	29	27	24	25	810.716.1	11,7
Pg 21	3/4"	13 - 18	67	12	35	33	30	25	810.721.1	19,6
Pg 29	1"	18 - 23,8	80	12	45	43	40	10	810.729.1	35,4

**Pg gerade EMV Kabel-Schlauch-Verschraubung, Aussen-  
gewinde, Messing-vernickelt.**

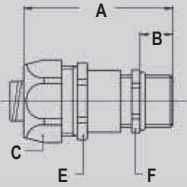

Gewinde	Sealtite	Klemm- bereich (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	E	F			
Pg 9	5/16"	4 - 8	55	10	26	24	17	25	810.609.1	7,8
Pg 9	3/8"	5 - 8	55	10	26	24	20	25	810.612.1	7,8
Pg 11	3/8"	5 - 10	55	10	26	24	20	25	810.611.1	9,5
Pg 13,5	1/2"	6 - 12	57	10	29	27	22	25	810.615.1	9,7
Pg 16	1/2"	10 - 13,9	60	10	29	27	24	25	810.616.1	11,7
Pg 21	3/4"	13 - 18	67	12	35	33	30	25	810.621.1	19,6
Pg 29	1"	18 - 23,8	80	12	45	43	40	10	810.629.1	35,4


**NPT gerade Verschraubung, Aussengewinde,  
Messing-vernickelt.**

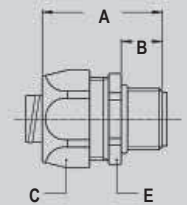

Gewinde	Sealtite	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	8,3	35	12	26	-	24	50	814.011.1*	5,6
1/2" NPT	3/8"	10,2	35	12	26	-	24	50	814.012.1	5,6
1/2" NPT	1/2"	13,9	37	13	29	-	27	50	814.016.1	6,2
3/4" NPT	3/4"	18,5	40	15	35	-	33	25	814.020.1	8,9
1" NPT	1"	23,8	46	15	45	-	43	10	814.026.1	25,0
1.1/4" NPT	1.1/4"	31,8	52	16	54	-	52	5	814.035.1	40,0
1.1/2" NPT	1.1/2"	36,8	56	18	63	-	60	5	814.040.1	43,8
2" NPT	2"	47,8	66	20	77	-	74	4	814.050.1	73,5
2.1/2" NPT	2.1/2"	59,0	72	24	95	-	90	4	814.063.1*	134,4
3" NPT	3"	71,5	80	28	110	-	105	2	814.075.1*	172,8
4" NPT	4"	96,0	92	32	145	-	135	2	814.099.1*	300,0

\* Verschraubungen für 1/4", 5/16", 2.1/2", 3" und 4" Schlauch ohne UL/CSA Zulassung.

**NPT gerade Verschraubung, Innengewinde,  
Messing-vernickelt.**

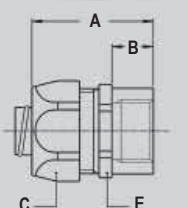

Gewinde	Sealtite	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	8,3	37	13	26	-	24	50	814.311.1*	5,3
1/2" NPT	3/8"	10,2	37	13	26	-	24	50	814.312.1	5,3
1/2" NPT	1/2"	13,9	37	13	29	-	27	50	814.316.1	6,2
3/4" NPT	3/4"	18,5	40	15	35	-	33	25	814.320.1	9,0
1" NPT	1"	23,8	46	15	45	-	43	10	814.326.1	20,7
1.1/4" NPT	1.1/4"	31,8	52	16	54	-	52	5	814.335.1	29,3
1.1/2" NPT	1.1/2"	36,8	56	18	63	-	60	5	814.340.1	43,8
2" NPT	2"	47,8	66	20	77	-	74	4	814.350.1	73,3

\* Verschraubungen für 5/16" Schlauch ohne UL/CSA Zulassung.

**ANACONDA  
VERSCHRAU-  
BUNGEN**

**VERSCHRAU-  
BUNGEN FÜR  
SEALTITE  
IP 67**