



Raccord mâle presse-étoupe ISO en laiton nickelé

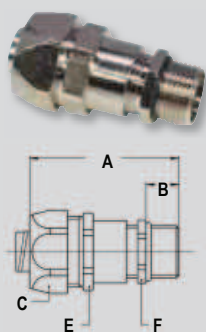


Filetage ISO	Sealtite (Pouce)	Diamètre de serrage (mm)	Dimensions en mm						Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	E	F				
M16 x 1,5	5/16"	4 - 8	57	12	26	24	18	10	812.715.2	5,2	
M16 x 1,5	3/8"	4 - 8	57	12	26	24	18	10	812.716.1	7,8	
M20 x 1,5	3/8"	6 - 10,2	57	12	26	24	22	10	812.717.1	9,5	
M20 x 1,5	1/2"	6 - 12	59	12	29	27	22	10	812.720.1	9,7	
M25 x 1,5	1/2"	10 - 13,9	62	12	29	27	27	5	812.722.1	11,7	
M32 x 1,5	3/4"	13 - 18	70	15	35	33	34	5	812.728.1	20,2	
M40 x 1,5	1"	18 - 23,8	83	15	45	43	43	2	812.735.1	32,6	
M50 x 1,5	1.1/4"	22 - 31,8	96	15	54	52	55	2	812.745.1	60,0	

Raccord CEM mâle presse-étoupe ISO en laiton nickelé

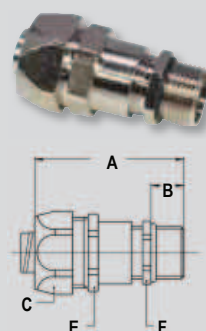

Filetage ISO	Sealtite (Pouce)	Diamètre de serrage (mm)	Dimensions en mm						Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	E	F				
M16 x 1,5	5/16"	4 - 8	57	12	26	24	18	10	812.615.2	5,2	
M16 x 1,5	3/8"	4 - 8	57	12	26	24	18	10	812.616.1	7,8	
M20 x 1,5	3/8"	6 - 10,2	57	12	26	24	22	10	812.617.1	9,5	
M20 x 1,5	1/2"	6 - 12	59	12	29	27	22	10	812.620.1	9,7	
M25 x 1,5	1/2"	10 - 13,9	62	12	29	27	27	5	812.622.1	11,7	
M32 x 1,5	3/4"	13 - 18	70	15	35	33	34	5	812.628.1	19,6	
M40 x 1,5	1"	18 - 23,8	83	15	45	43	43	2	812.635.1	35,4	


Raccord mâle droit Pg en laiton nickelé

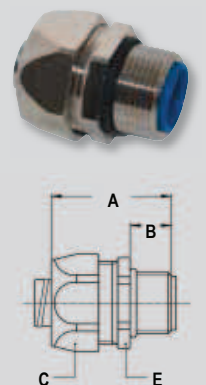

Filetage Pg	Sealtite (Pouce)	Diam. intérieur Min. (mm)	Dimensions en mm						Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	D	E				
Pg 7	1/4"	5,2	33	10	22	-	20	10	810.007.1*	3,0	
Pg 9	5/16"	8,3	35	12	26	-	24	10	810.009.1*	4,8	
Pg 11	5/16"	8,3	35	12	26	-	24	10	810.012.1*	5,6	
Pg 13,5	5/16"	8,3	35	12	26	-	24	10	810.014.1*	5,6	
Pg 9	3/8"	10,2	35	12	26	-	24	10	810.010.1	4,8	
Pg 11	3/8"	10,2	35	12	26	-	24	10	810.011.1	5,6	
Pg 13,5	3/8"	10,2	35	12	26	-	24	10	810.013.1	5,6	
Pg 16	1/2"	13,9	37	13	29	-	27	10	810.016.1	6,3	
Pg 21	3/4"	18,5	40	15	35	-	33	5	810.021.1	8,4	
Pg 29	1"	23,8	46	15	45	-	43	5	810.029.1	25,0	
Pg 36	1.1/4"	31,8	52	16	54	-	52	2	810.036.1	34,6	
Pg 42	1.1/2"	36,8	56	18	63	-	60	2	810.042.1	47,2	
Pg 48	2"	47,8	66	20	77	-	74	2	810.048.1	72,0	

* Raccords pour gaines 1/4" e 5/16" sans homologation UL/CSA.

Raccord mâle droit Pg, petit modèle, en laiton nickelé

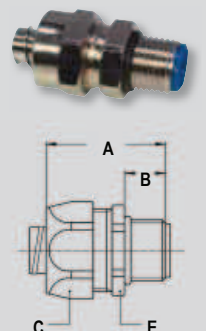

Filetage Pg	Sealtite (Pouce)	Diam. intérieur Min. (mm)	Dimensions en mm						Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	D	E				
Pg 7	1/4"	5,2	33	10	19	-	17	10	810.007.2	2,8	
Pg 9	5/16"	8,3	35	12	22	-	20	10	810.009.2	3,8	

RACCORDS
ANACONDA

RACCORDS
POUR GAINES
SEALTITE
IP 67