



### Raccordo NPT maschio diritto in ottone nichelato (incluso adattatore per UIG/UI)

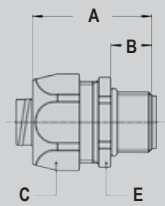


Filetto NPT	UIG/UI Ø (inch)	Passaggio utile (mm)	Dimensioni in mm					Confezione standard	Codice articolo	Peso (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	6,8	35	12	26	-	24	50	814.011.7	5,6
1/2" NPT	3/8"	9,8	35	12	26	-	24	50	814.012.7	5,6
1/2" NPT	1/2"	13,9	37	13	29	-	27	50	814.016.7	6,2
3/4" NPT	3/4"	18,5	40	15	35	-	33	25	814.020.7	8,9
1" NPT	1"	22,8	46	15	45	-	43	10	814.026.7	17,9
1.1/4" NPT	1.1/4"	30,8	52	16	54	-	52	5	814.035.7	40,0
1.1/2" NPT	1.1/2"	36,8	56	18	63	-	60	5	814.040.7	43,8
2" NPT	2"	47,8	66	20	77	-	74	4	814.050.7	73,5

### Raccordo NPT femmina in ottone nichelato (incluso adattatore per UIG /UI)

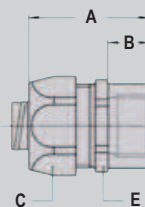



Filetto NPT	UIG/UI Ø (inch)	Passaggio utile (mm)	Dimensioni in mm					Confezione standard	Codice articolo	Peso (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	6,8	37	13	26	-	24	50	814.311.7	5,3
1/2" NPT	3/8"	9,8	37	13	26	-	24	50	814.312.7	5,3
1/2" NPT	1/2"	13,9	37	13	29	-	27	50	814.316.7	6,2
3/4" NPT	3/4"	18,5	40	15	35	-	33	25	814.320.7	9,0
1" NPT	1"	22,8	46	15	45	-	43	10	814.326.7	20,7
1.1/4" NPT	1.1/4"	30,8	52	16	54	-	52	5	814.335.7	29,3
1.1/2" NPT	1.1/2"	36,8	56	18	63	-	60	5	814.340.7	43,8
2" NPT	2"	47,8	66	20	77	-	74	4	814.350.7	73,3

### Raccordo NPT maschio 90° in ottone nichelato (incluso adattatore per UIG/UI)

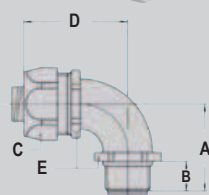

Filetto NPT	UIG/UI Ø (inch)	Passaggio utile (mm)	Dimensioni in mm					Confezione standard	Codice articolo	Peso (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	6,8	32	12	26	42	22	50	814.911.7	13,3
1/2" NPT	3/8"	9,8	32	12	26	42	22	50	814.912.7	13,3
1/2" NPT	1/2"	13,9	36	13	29	43	27	50	814.916.7	14,6
3/4" NPT	3/4"	18,5	43	15	35	48	33	25	814.920.7	22,0
1" NPT	1"	22,8	48	15	45	59	42	10	814.926.7	31,7
1.1/4" NPT	1.1/4"	30,8	57	16	54	68	51	5	814.935.7	62,5
1.1/2" NPT	1.1/2"	36,8	63	18	63	78	60	5	814.940.7	89,1
2" NPT	2"	47,8	74	20	77	96	74	4	814.950.7	141,9

### Raccordo-pressacavo NPT maschio diritto in ottone nichelato (incluso adattatore per UIG/UI)

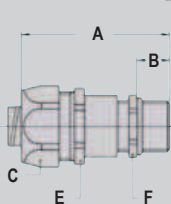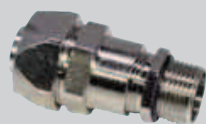

Filetto NPT	UIG/UI Ø (inch)	Ø cavo min-max (mm)	Dimensioni in mm					Confezione standard	Codice articolo	Peso (Kg/100)
			A	B	C	E	F			
3/8" NPT	5/16"	4 - 6,8	60	15	26	24	17	25	814.709.7	7,8
3/8" NPT	3/8"	4 - 8	60	15	26	24	17	25	814.710.7	7,8
1/2" NPT	3/8"	6 - 9,8	57	13	26	24	22	25	814.712.7	11,7
1/2" NPT	1/2"	6 - 12	59	13	29	27	22	25	814.715.7	11,7
3/4" NPT	3/4"	13 - 18	68	13	35	33	30	25	814.721.7	19,6

ANACONDA  
MULTIFLEX

RACCORDI  
PER UIG/UI  
IP 40