



**ISO gerade Kabel-Schlauch-Verschraubung, Silikon
Dichtung bis max. +300 °C (einschl. Einschraubset).**

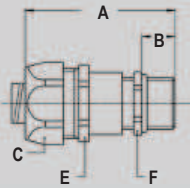


Gewinde ISO	UIG / UI NW (Zoll)	Klemm- bereich (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	E	F			
M16 x 1,5	5/16"	4 - 6	50	5	26	24	18	25	812.715.4	7,4
M16 x 1,5	3/8"	4 - 9	50	5	26	24	18	25	812.716.4	9,4
M20 x 1,5	1/2"	4,5 - 12	53	6	29	27	22	25	812.720.4	11,5
M25 x 1,5	1/2"	10 - 13	57	7	29	27	28	25	812.722.4	13,5

**ISO gerade EMV Kabel-Schlauch-Verschraubung, Aussen-
gewinde, Messing-vernickelt (einschl. Einschraubset).**

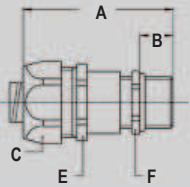


Gewinde ISO	UIG / UI NW (Zoll)	Klemm- bereich (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	E	F			
M16 x 1,5	5/16"	4 - 6,8	57	12	26	24	18	25	812.615.7	7,4
M16 x 1,5	3/8"	4 - 8	57	12	26	24	18	25	812.616.7	9,4
M20 x 1,5	3/8"	6 - 9,8	57	12	26	24	22	25	812.617.7	11,1
M20 x 1,5	1/2"	6 - 12	59	12	29	27	22	25	812.620.7	11,5
M25 x 1,5	1/2"	10 - 13,9	62	12	29	27	27	25	812.622.7	13,5
M32 x 1,5	3/4"	13 - 18	70	15	35	33	34	25	812.628.7	22,6
M40 x 1,5	1"	18 - 22,8	83	15	45	43	43	10	812.635.7	38,0

**Pg gerade Verschraubung, Aussengewinde, Messing-
vernickelt (einschl. Einschraubset).**

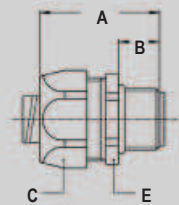

Gewinde Pg	UIG / UI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 9	5/16"	6,8	35	12	26	-	24	50	810.009.7	6,4
Pg 11	5/16"	6,8	35	12	26	-	24	50	810.012.7	7,2
Pg 9	3/8"	9,8	35	12	26	-	24	50	810.010.7	6,4
Pg 11	3/8"	9,8	35	12	26	-	24	50	810.011.7	7,2
Pg 13,5	3/8"	9,8	35	12	26	-	24	50	810.013.7	7,2
Pg 16	1/2"	13,9	37	13	29	-	27	50	810.016.7	8,1
Pg 21	3/4"	18,5	40	15	35	-	33	25	810.021.7	11,4
Pg 29	1"	22,8	46	15	45	-	43	10	810.029.7	27,6
Pg 36	1.1/4"	30,8	52	16	54	-	52	5	810.036.7	38,4
Pg 42	1.1/2"	36,8	56	18	63	-	60	5	810.042.7	52,8
Pg 48	2"	47,8	66	20	77	-	74	4	810.048.7	81,4

**Pg gerade Verschraubung, Innengewinde, Messing-
vernickelt (einschl. Einschraubset).**

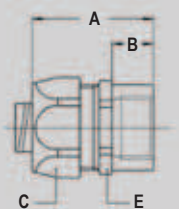

Gewinde Pg	UIG / UI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 11	5/16"	6,8	35	12	26	-	24	50	810.312.7	6,7
Pg 11	3/8"	9,8	35	12	26	-	24	50	810.311.7	6,9
Pg 13,5	3/8"	9,8	35	12	26	-	24	50	810.313.7	7,4
Pg 16	1/2"	13,9	37	13	29	-	27	50	810.316.7	8,1
Pg 21	3/4"	18,5	40	15	35	-	33	25	810.321.7	12,3
Pg 29	1"	22,8	46	15	45	-	43	10	810.329.7	23,3
Pg 36	1.1/4"	30,8	52	16	54	-	52	5	810.336.7	33,1
Pg 42	1.1/2"	36,8	56	18	63	-	60	5	810.342.7	48,8
Pg 48	2"	47,8	66	20	77	-	74	4	810.348.7	84,2