



## Raccord CEM mâle presse-étoupe ISO en laiton nickelé (kit de raccordement inclus)

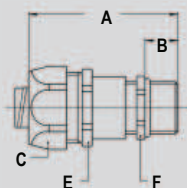


| Filetage<br>ISO | UI et UIG<br>(Pouce) | Diamètre de<br>serrage (mm) | Dimensions en mm |    |    |    |    | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|-----------------|----------------------|-----------------------------|------------------|----|----|----|----|------------------------|----------------------|-------------------|
|                 |                      |                             | A                | B  | C  | E  | F  |                        |                      |                   |
| M16 x 1,5       | 5/16"                | 4 - 6,8                     | 57               | 12 | 26 | 24 | 18 | 10                     | 812.615.7            | 7,4               |
| M16 x 1,5       | 3/8"                 | 4 - 8                       | 57               | 12 | 26 | 24 | 18 | 10                     | 812.616.7            | 9,4               |
| M20 x 1,5       | 3/8"                 | 6 - 9,8                     | 57               | 12 | 26 | 24 | 22 | 10                     | 812.617.7            | 11,1              |
| M20 x 1,5       | 1/2"                 | 6 - 12                      | 59               | 12 | 29 | 27 | 22 | 10                     | 812.620.7            | 11,5              |
| M25 x 1,5       | 1/2"                 | 10 - 13,9                   | 62               | 12 | 29 | 27 | 27 | 5                      | 812.622.7            | 13,5              |
| M32 x 1,5       | 3/4"                 | 13 - 18                     | 70               | 15 | 35 | 33 | 34 | 5                      | 812.628.7            | 22,6              |
| M40 x 1,5       | 1"                   | 18 - 22,8                   | 83               | 15 | 45 | 43 | 43 | 2                      | 812.635.7            | 38,0              |

## Raccord mâle droit Pg en laiton nickelé (kit de raccordement inclus)

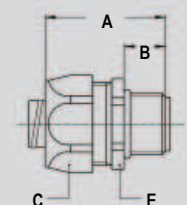


| Filetage<br>Pg | UI et UIG<br>(Pouce) | Diam. intérieur<br>Min. (mm) | Dimensions en mm |    |    |   |    | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|----------------|----------------------|------------------------------|------------------|----|----|---|----|------------------------|----------------------|-------------------|
|                |                      |                              | A                | B  | C  | D | E  |                        |                      |                   |
| Pg 9           | 5/16"                | 6,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.009.7            | 6,4               |
| Pg 11          | 5/16"                | 6,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.012.7            | 7,2               |
| Pg 9           | 3/8"                 | 9,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.010.7            | 6,4               |
| Pg 11          | 3/8"                 | 9,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.011.7            | 7,2               |
| Pg 13,5        | 3/8"                 | 9,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.013.7            | 7,2               |
| Pg 16          | 1/2"                 | 13,9                         | 37               | 13 | 29 | - | 27 | 10                     | 810.016.7            | 8,1               |
| Pg 21          | 3/4"                 | 18,5                         | 40               | 15 | 35 | - | 33 | 5                      | 810.021.7            | 11,4              |
| Pg 29          | 1"                   | 22,8                         | 46               | 15 | 45 | - | 43 | 5                      | 810.029.7            | 27,6              |
| Pg 36          | 1.1/4"               | 30,8                         | 52               | 16 | 54 | - | 52 | 2                      | 810.036.7            | 38,4              |
| Pg 42          | 1.1/2"               | 36,8                         | 56               | 18 | 63 | - | 60 | 2                      | 810.042.7            | 52,8              |
| Pg 48          | 2"                   | 47,8                         | 66               | 20 | 77 | - | 74 | 2                      | 810.048.7            | 81,4              |

## Raccord femelle droit Pg en laiton nickelé (kit de raccordement inclus)

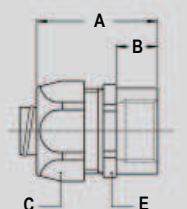

| Filetage<br>Pg | UI et UIG<br>(Pouce) | Diam. intérieur<br>Min. (mm) | Dimensions en mm |    |    |   |    | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|----------------|----------------------|------------------------------|------------------|----|----|---|----|------------------------|----------------------|-------------------|
|                |                      |                              | A                | B  | C  | D | E  |                        |                      |                   |
| Pg 11          | 5/16"                | 6,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.312.7            | 6,7               |
| Pg 11          | 3/8"                 | 9,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.311.7            | 6,9               |
| Pg 13,5        | 5/16"                | 6,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.314.7            | 7,2               |
| Pg 13,5        | 3/8"                 | 9,8                          | 35               | 12 | 26 | - | 24 | 10                     | 810.313.7            | 7,4               |
| Pg 16          | 1/2"                 | 13,9                         | 37               | 13 | 29 | - | 27 | 10                     | 810.316.7            | 8,1               |
| Pg 21          | 3/4"                 | 18,5                         | 40               | 15 | 35 | - | 33 | 5                      | 810.321.7            | 12,3              |
| Pg 29          | 1"                   | 22,8                         | 46               | 15 | 45 | - | 43 | 5                      | 810.329.7            | 23,3              |
| Pg 36          | 1.1/4"               | 30,8                         | 52               | 16 | 54 | - | 52 | 2                      | 810.336.7            | 33,1              |
| Pg 42          | 1.1/2"               | 36,8                         | 56               | 18 | 63 | - | 60 | 2                      | 810.342.7            | 48,8              |
| Pg 48          | 2"                   | 47,8                         | 66               | 20 | 77 | - | 74 | 2                      | 810.348.7            | 84,2              |

## Raccord mâle droit Pg tournant en laiton nickelé (kit de raccordement inclus)

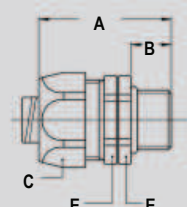

| Filetage<br>Pg | UI et UIG<br>(Pouce) | Diam. intérieur<br>Min. (mm) | Dimensions en mm |    |    |   |    | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|----------------|----------------------|------------------------------|------------------|----|----|---|----|------------------------|----------------------|-------------------|
|                |                      |                              | A                | B  | C  | D | E  |                        |                      |                   |
| Pg 9           | 5/16"                | 6,8                          | 41               | 12 | 26 | - | 24 | 10                     | 811.009.7            | 8,2               |
| Pg 11          | 3/8"                 | 9,8                          | 41               | 12 | 26 | - | 24 | 10                     | 811.011.7            | 8,4               |
| Pg 16          | 1/2"                 | 13,9                         | 43               | 13 | 29 | - | 27 | 10                     | 811.016.7            | 10,6              |
| Pg 21          | 3/4"                 | 18,5                         | 48               | 15 | 35 | - | 33 | 5                      | 811.021.7            | 16,6              |
| Pg 29          | 1"                   | 22,8                         | 54               | 15 | 45 | - | 43 | 5                      | 811.029.7            | 30,0              |

ANACONDA  
MULTIFLEX

RACCORDS  
POUR GAINES  
UI ET UIG  
IP 40