

Raccordo ISO femmina diritto fisso in ottone nichelato




| Filetto | FCD / FCE Ø (DN) | Passaggio utile (mm) | Dimensioni in mm | | | | | Confezione standard | Codice articolo | Peso (Kg/100) |
|-----------|---------------------|-------------------------|------------------|----|----|---|---|------------------------|--------------------|------------------|
| | | | A | B | C | D | E | | | |
| M16 x 1,5 | 16 | 11,2 | 29 | 13 | 20 | - | - | 10 | 260.316.0 | 2,4 |
| M20 x 1,5 | 16 | 11,2 | 30 | 13 | 24 | - | - | 10 | 260.317.0 | 3,0 |
| M20 x 1,5 | 20 | 15,2 | 30 | 13 | 24 | - | - | 10 | 260.320.0 | 3,2 |
| M25 x 1,5 | 25 | 19,2 | 34 | 15 | 30 | - | - | 5 | 260.325.0 | 5,9 |
| M32 x 1,5 | 32 | 25,9 | 39 | 16 | 38 | - | - | 5 | 260.332.0 | 8,5 |
| M40 x 1,5 | 40 | 34,8 | 43 | 16 | 48 | - | - | 2 | 260.340.0 | 16,6 |
| M50 x 1,5 | 50 | 44,8 | 47 | 17 | 60 | - | - | 2 | 260.350.0 | 24,5 |

**ANACONDA
MULTITITE**


**RACCORDI PER
MULTITITE
IP 54**

Raccordo Pg maschio diritto fisso in ottone nichelato

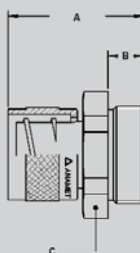

| Filetto Pg | FCD / FCE Ø (DN) | Passaggio utile (mm) | Dimensioni in mm | | | | | Confezione standard | Codice articolo | Peso (Kg/100) |
|---------------|---------------------|-------------------------|------------------|----|----|---|---|------------------------|--------------------|------------------|
| | | | A | B | C | D | E | | | |
| Pg 7 | 10 | 5,5 | 24 | 8 | 14 | - | - | 10 | 260.207.0 | 1,3 |
| Pg 9 | 12 | 8,5 | 26 | 10 | 18 | - | - | 10 | 260.209.0 | 1,9 |
| Pg 11 | 16 | 11,2 | 27 | 10 | 20 | - | - | 10 | 260.211.0 | 2,4 |
| Pg 13,5 | 18 | 13,2 | 27 | 10 | 24 | - | - | 10 | 260.213.0 | 3,0 |
| Pg 16 | 20 | 15,2 | 27 | 10 | 24 | - | - | 10 | 260.216.0 | 3,2 |
| Pg 21 | 25 | 19,2 | 32 | 12 | 30 | - | - | 5 | 260.221.0 | 5,5 |
| Pg 29 | 32 | 25,9 | 35 | 13 | 38 | - | - | 5 | 260.229.0 | 8,9 |
| Pg 36 | 40 | 34,8 | 41 | 14 | 50 | - | - | 2 | 260.236.0 | 19,0 |
| Pg 48 | 50 | 44,8 | 45 | 16 | 65 | - | - | 2 | 260.248.0 | 25,3 |

Raccordo Pg maschio diritto girevole in ottone nichelato

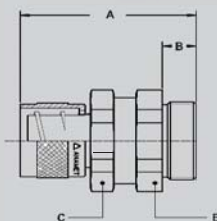

| Filetto Pg | FCD / FCE Ø (DN) | Passaggio utile (mm) | Dimensioni in mm | | | | | Confezione standard | Codice articolo | Peso (Kg/100) |
|---------------|---------------------|-------------------------|------------------|----|----|---|----|------------------------|--------------------|------------------|
| | | | A | B | C | D | E | | | |
| Pg 7 | 10 | 5,5 | 30 | 8 | 14 | - | 14 | 10 | 261.207.0 | 1,8 |
| Pg 9 | 12 | 8,5 | 34 | 10 | 18 | - | 18 | 10 | 261.209.0 | 3,0 |
| Pg 11 | 16 | 11,2 | 36 | 10 | 20 | - | 20 | 10 | 261.211.0 | 4,0 |
| Pg 13,5 | 18 | 13,2 | 36 | 10 | 24 | - | 24 | 10 | 261.213.0 | 4,6 |
| Pg 16 | 20 | 15,2 | 37 | 10 | 24 | - | 24 | 10 | 261.216.0 | 5,2 |
| Pg 21 | 25 | 19,2 | 43 | 12 | 30 | - | 30 | 5 | 261.221.0 | 9,2 |
| Pg 29 | 32 | 25,9 | 47 | 13 | 38 | - | 40 | 5 | 261.229.0 | 14,6 |
| Pg 36 | 40 | 34,8 | 56 | 14 | 48 | - | 50 | 2 | 261.236.0 | 27,3 |
| Pg 48 | 50 | 44,8 | 61 | 16 | 60 | - | 65 | 2 | 261.248.0 | 43,8 |