



# CP 8000 V1


Heavy Load

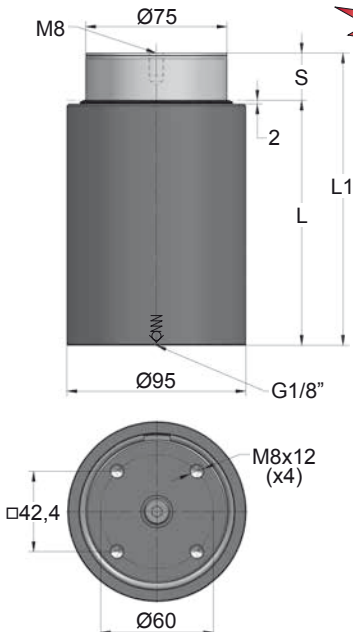


ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
CP 8000 010 V1	10	110	100	4.24
CP 8000 015 V1	15	135	120	4.64
CP 8000 025 V1	25	155	130	4.99
CP 8000 038 V1	38	185	147	5.50
CP 8000 050 V1	50	215	165	6.00
CP 8000 063 V1	63	255	192	6.66
CP 8000 080 V1	80	290	210	7.26

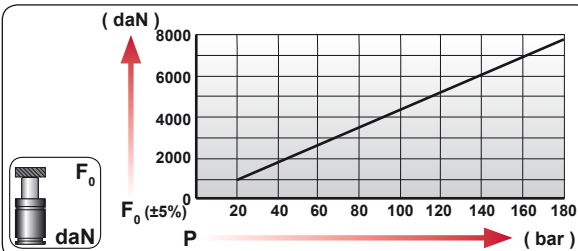

CODE	Pressure (bar/psi)	F <sub>0</sub> (daN)	F <sub>1</sub> (daN)
CP 8000 050 V1	180 / 2610	7950	13530
-----	-----	-----	-----

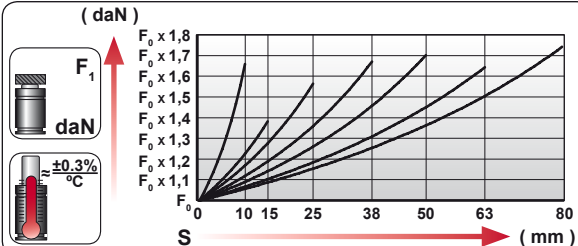

	ENG ORDER DEU BESTELLUNG FRA COMMANDE ITA ORDINE ESP PEDIDO POR PEDIDO		
		F <sub>0</sub> daN	S mm
		8000	50
		CP 8000 050 V1	

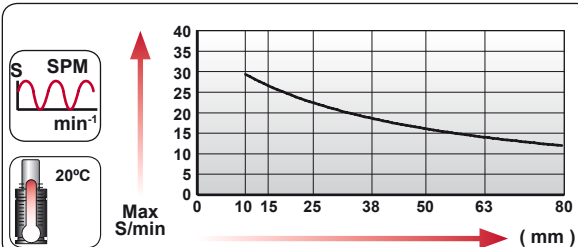






N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 0,5 m/s	P <sub>min</sub> (20°C)	P <sub>max</sub> (20°C)	T <sub>min</sub> T <sub>max</sub>	

N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 0,5 m/s	bar psi	bar psi	°C °F	°C °F	°C °F	°C °F	✗
			20 290	180 2610	0 32	80 176			

# CP 8000 V1 MOUNTS

  Heavy Load

	50	50	50	50	50	50	50	50
	Ø95	Ø95	Ø95	Ø95	Ø95	Ø95	Ø95	Ø95
	L1=158 L1=162	L1=170 L1=170	L1=195 L1=205 L1=220	L1=220	L1=215	L1=255		
MODEL	✗	CW 4200 KZ 4200	✗	CK 4000 FD 3000	GN 3000 CM 4000 CD 4200	AG 3000	CP 8000	CS 7500
SERIES	MINI 	COMPACT HEIGHT 	THREADED 	LOW PROFILE 	HEAVY DUTY 	ISO 	HEAVY LOAD 	POWER COMPACT STROKE 

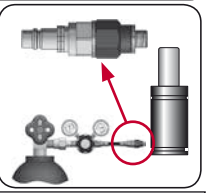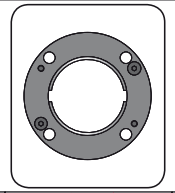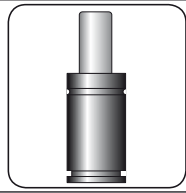

CODE	CP 8000 050 V1	KIT S-XXXXXXX	✗	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	FLANGE	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	FLANSCHEN	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	BRIDE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	FLANGE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	BRIDA	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	FLANGE	ADAPTADOR DE CARGA