


# AZOL GAS ROT 5000



Special Applications

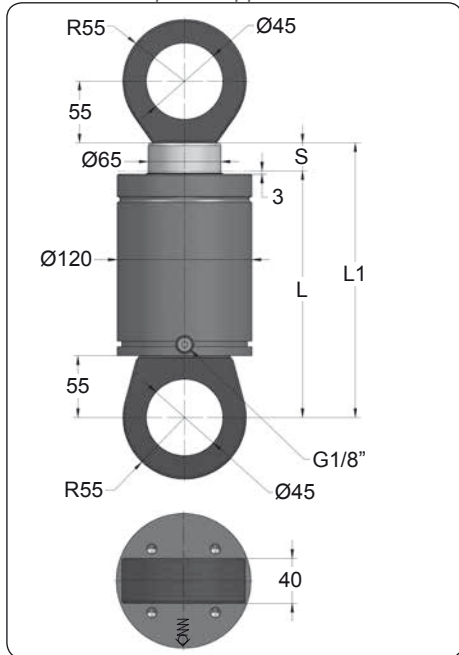

ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
ROT 5000 012	12.7	220.4	207.7	15.79
ROT 5000 025	25	245	220	16.96
ROT 5000 038	38	271	233	17.11
ROT 5000 050	50	295	245	17.45
ROT 5000 063	63.5	322	258.5	18.17
ROT 5000 080	80	355	275	19.76
ROT 5000 100	100	395	295	20.21
ROT 5000 125	125	445	320	21.56
ROT 5000 160	160	515	355	23.36



CODE				
		bar psi	daN	daN
ROT 5000 050		150 2175	4980	7170
-----		-----	-----	-----

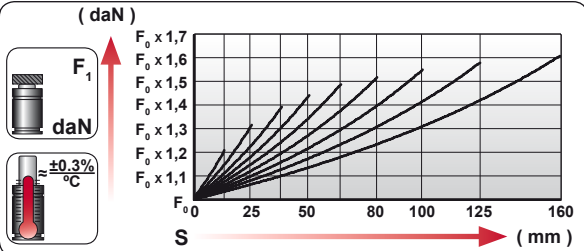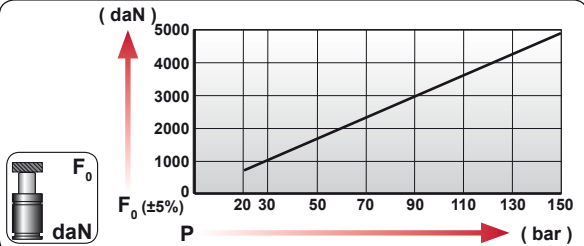

	ENG ORDER		
	DEU BESTELLUNG		
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

**ROT 5000 50**

**ROT 5000 050**

SEAL KIT S-XXXXXXX  
 CARTRIDGE KIT C-XXXXXXX

**KIT S-XXXXXXX**  
**KIT C-XXXXXXX**

**18 CG 1-Q**

ENG REPAIR KIT	CHARGING ADAPTER
DEU ERSATZ	LADEADAPTER
FRA KIT DE RÉPARATION	RACCORD DE CHARGE
ITA KIT DI MANUTENZIONE	ADATTATORE DI CARICO
ESP KIT DE REPARACION	ADAPTADOR DE CARGA
POR KIT DE MANUTENÇÃO	ADAPTADOR DE CARGA

N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 1,6 m/s	bar psi 20 290	bar psi 150 2175	°C °F 0 32	°C °F 80 176	600 CP-