


RGR

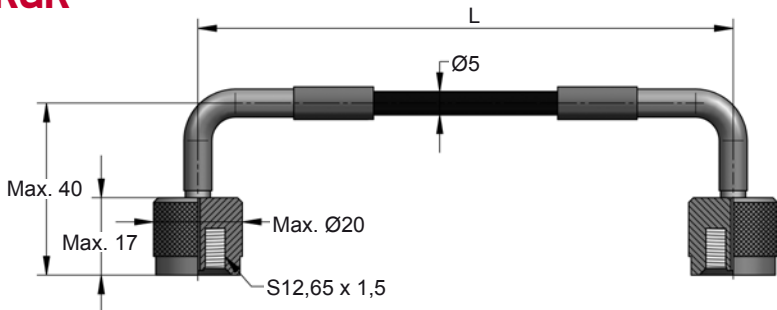


ORDER	L ⁺⁵ ₋₀ (mm)
RGR 200	200
RGR 300	300
RGR 400	400
RGR 500	500
RGR 630	630
RGR 800	800
RGR 1000	1000
RGR 1200	1200
RGR 1250	1250
RGR 1500	1500
RGR 2000	2000
RGR 2500	2500
RGR 3000	3000



ENG ORDER
DEU BESTELL
FRA COMMANDE
ITA ORDINE
ESP PEDIDO
POR PEDIDO



PGP

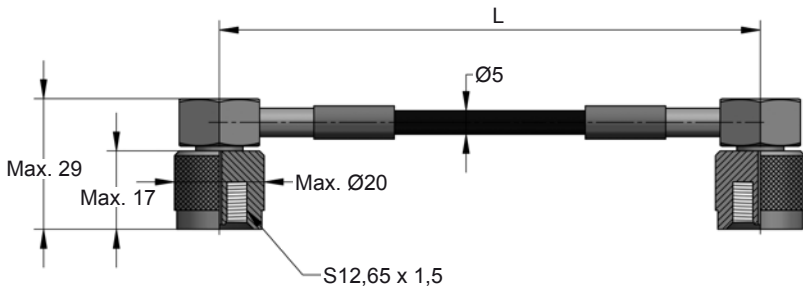

ORDER	L ⁺⁵ ₋₀ (mm)
PGP 200	200
PGP 300	300
PGP 400	400
PGP 500	500
PGP 630	630
PGP 800	800
PGP 1000	1000
PGP 1200	1200
PGP 1250	1250
PGP 1500	1500
PGP 2000	2000
PGP 2500	2500
PGP 3000	3000




ENG ORDER
DEU BESTELL
FRA COMMANDE
ITA ORDINE
ESP PEDIDO
POR PEDIDO




EM.24.54.700
90.25
W-DX35-72
SMS DNH 3217n


GST

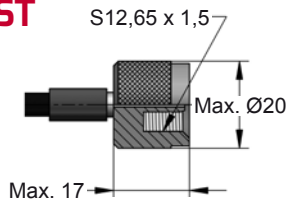

GPT

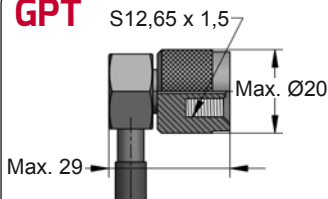

GRT

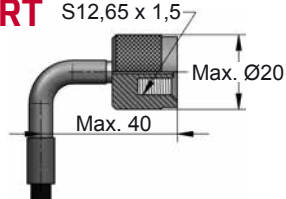

GF 02




Pmax
630 bar


Tmax
100 °C

Rmin
20 mm

RBP 5

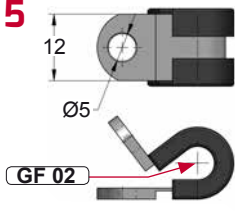

CM 1/8

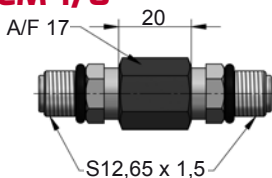


G1/8" MINIMESS




Accessories


SKK 12R 1/8

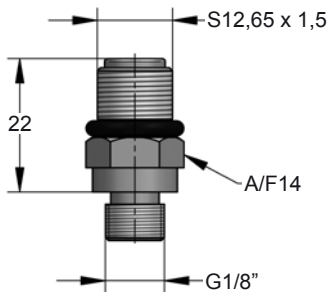



SKK L

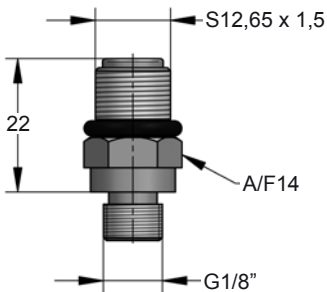



SKK 12R 1/4

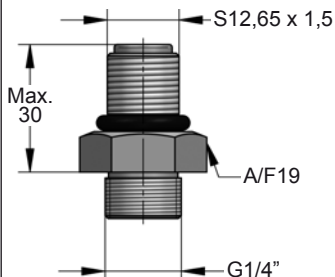



CF 01 24

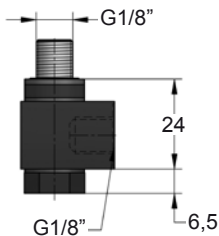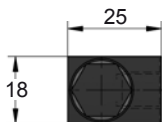



CF 01 38

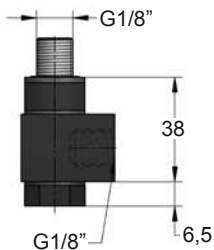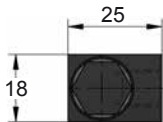



CF 01 48

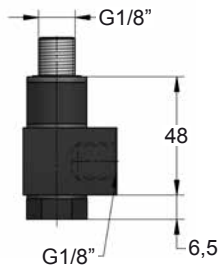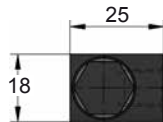



CF 02 26

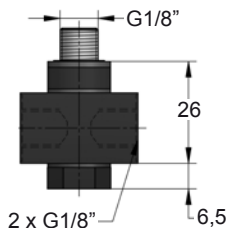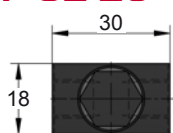


CF 02 40

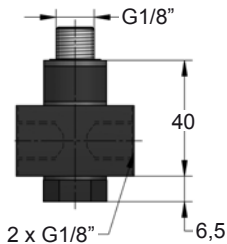 


CF 02 50

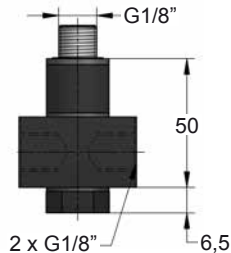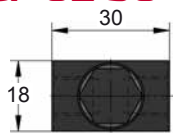


CF 03 34

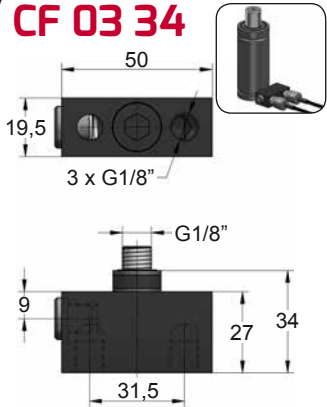


CF 03 48

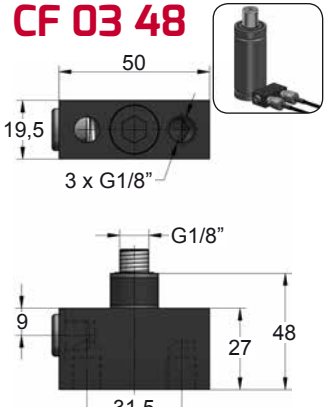


CF 03 55

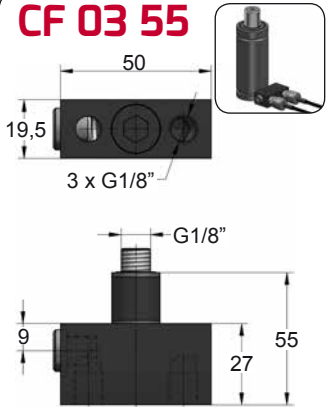


CF 04 26

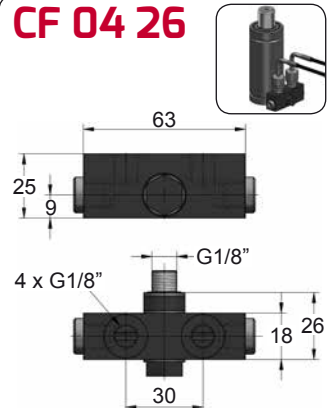


CF 04 40

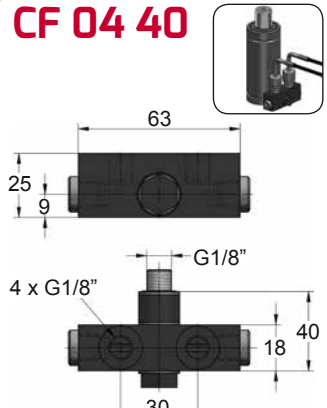


CF 04 50

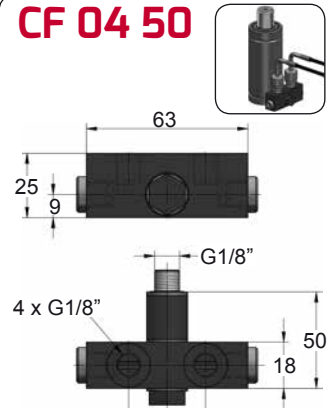

CF 05 27

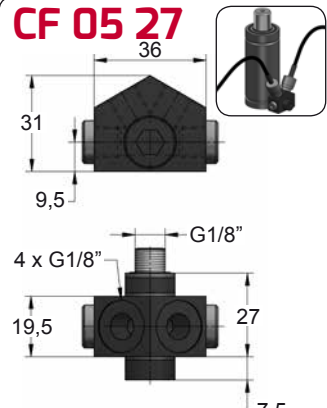

CF 05 41

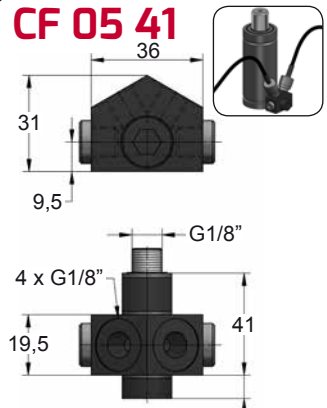

CF 05 48

