
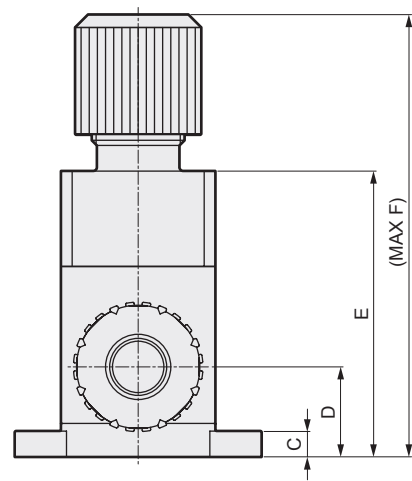
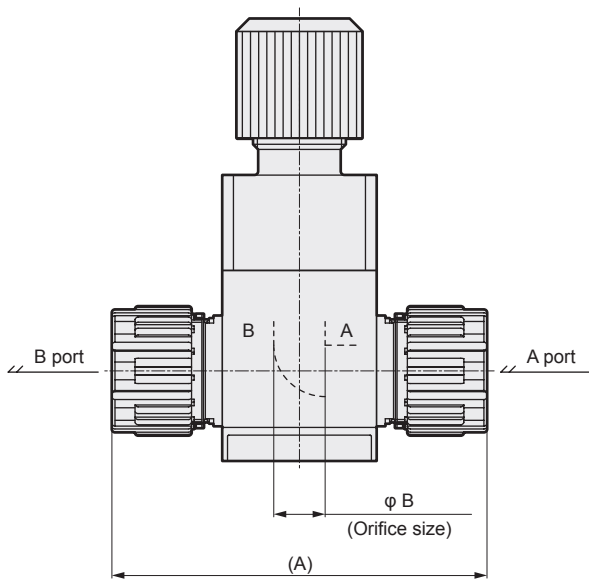


● MMD*03R

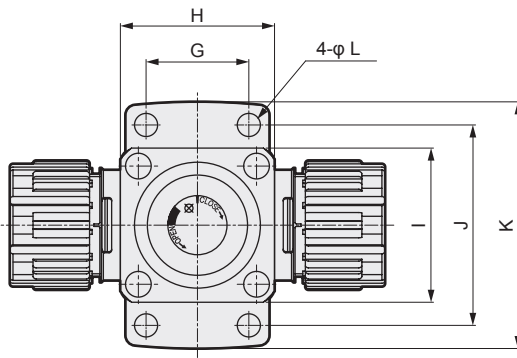

Model no.	A	B	C	D	E	F	G	H	I	J	K	L
MMD303R-10BUP-8	86	8	8.5	21	62	110	22	38	36	50	62	7
MMD303R-15BUP-10	94	10	8.5	21	62	110	22	38	36	50	62	7
MMD403R-20BUP-16	118	16	9	27	80	138	28	47	46	64	82	9
MMD503R-25BUP-20	146	20	10	35	111	180	40	60	60	78	96	9