


Sprężyny poliuretanowe

Polyurethane springs

Typ **SU-L**
Type

Przykład zamawiania:
Example order.

SU-L050080
80 ShoreA
D= 50mm
L = 80mm

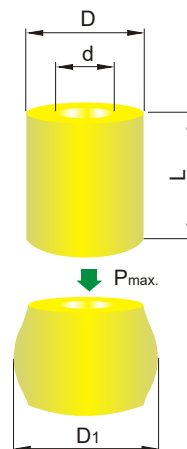

Średnica Diameter D [mm]	Max. obciążenie Max. Load [N]	d [mm]	D1 [mm]	80 Shore A												
				L [mm]												
				12	16	20	25	32	40	50	63	80	100	125	160	
Obciążenie [N] na każdy mm ugięcia Load [N] for each mm of compression																
16	480	6,5	21,3	90	80	70	55									
20	1000	8,5	26,6		180	143	115	90								
25	1900	10,5	33,3			270	218	173	136							
32	2500	13,5	42,6					227	178	142	114					
40	4700	13,5	53,2					427	335	268	214	167				
50	9000	18,0	66,5					807	643	514	410	320	257			
63	12800	18,0	83,8					1143	914	730	582	457	366	293		
80	21000	21,0	106,4					1875	1500	1200	955	750	600	480		
100	38000	21,0	133,0					3400	2720	2172	1727	1360	1086	870		
125	48000	27,0	166,3					4275	3420	2742	2182	1710	1371	1100	860	
Max. ugięcie [mm] Max. compression [mm]			35%	4,2	5,6	7,0	8,7	11,2	14,0	17,5	22,0	28,0	35,0	43,7	56,0	