


INDUCTIVE PROXIMITY SWITCH



2018.00.60.08.030

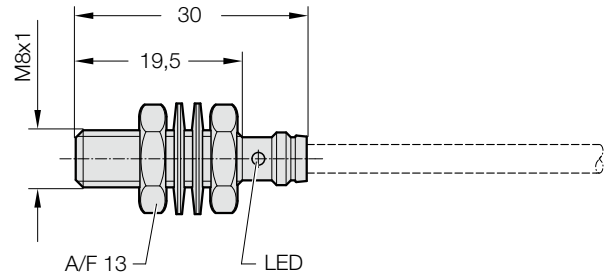

Technical data:

Rated operating voltage U_e : 24 V DC
Operating Voltage U_s : 10 - 30 V DC
No load current I_0 damped/undamped: $\leq 8 \text{ mA}/\leq 1 \text{ mA}$
Repeat accuracy R: $\leq 5\%$
Ambient temperature T_a : -40 to +85 °C
Switching frequency f : 3000 Hz
Degree of protection to IEC 529: IP 67
Casing material: Stainless steel
Connection: plug connector
Approvals: UL

2018.00.60.08.030

**Inductive proximity
switch**