

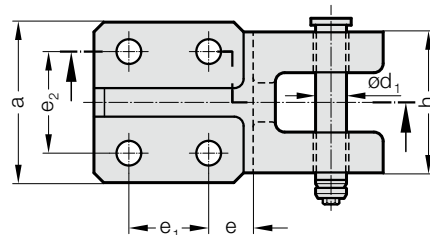


# NOSNÉ RAMENO S ČEPEM A S POJISTNÝM KROUŽKEM

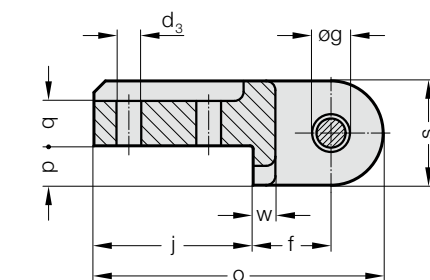

2133.12.




A

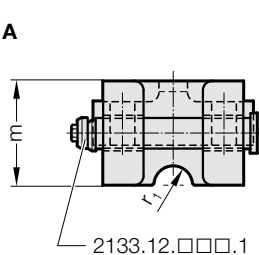

## Upozornění:

Objednací číslo pro náhradní díl čep s pojistným kroužkem:  
2133.12.□□□.1

B

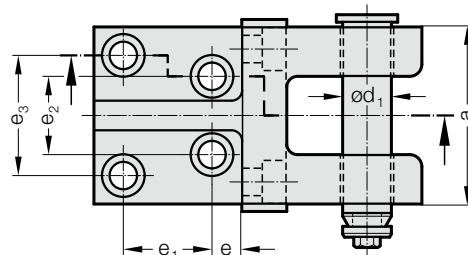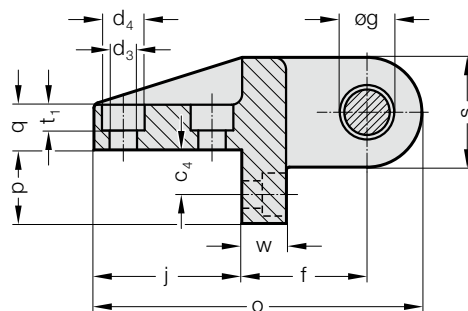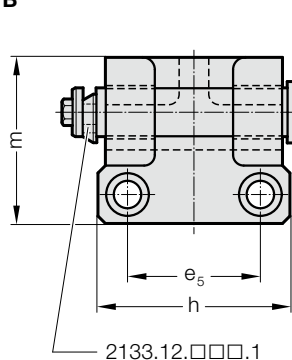

## 2133.12. Nosné rameno s čepem a s pojistným kroužkem

Objednací číslo	Tvar	max. Nosnost v páru (2 x Nosná ramena) [kg]*											g									
			d <sub>1</sub>	d <sub>3</sub>	d <sub>4</sub>	e	e <sub>1</sub>	e <sub>2</sub>	e <sub>3</sub>	e <sub>5</sub>	f	H13	h	j	m	o	p	q	r <sub>1</sub>	s	t <sub>1</sub>	w
2133.12.016	A	1 200	15.6	12.5	-	22.5	40	50	50	-	39	16	70	80	52	145	20	22	10	52	-	11
2133.12.021	A	2 000	20.6	16.5	-	27.5	40	60	60	-	42	21	79	90	56	160	20	26	12	56	-	13
2133.12.026	A	4 000	25.6	21	-	32.5	65	65	65	-	60	26	90	120	70	215	20	40	15	70	-	20
2133.12.034	B	8 000	33	18	28	20	60	56	84	96	85	34	135	100	111	221	50	30	0	72	17	30
2133.12.044	B	14 000	43	22	36	30	70	80	110	130	100	44	180	125	140	270	60	40	0	90	21	40

\*Maximální přípustná nosnost je vždy dimenzována pro dvě nosná ramena schopná nástroj nést nebo obrátit.