


## KALDIRMA VIDALI VDI 3366

### KALDIRMA VIDALI KABLO KORUMA EKIPMANLI



213.12.

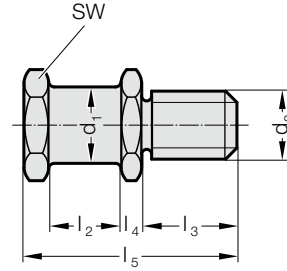


#### 213.12. Kaldırma vidalı VDI 3366

| Sipariş No. | d <sub>1</sub> | d <sub>3</sub> | l <sub>2</sub> | l <sub>3</sub> | l <sub>4</sub> | l <sub>5</sub> | SW* | Kapasitesi [kg] |
|-------------|----------------|----------------|----------------|----------------|----------------|----------------|-----|-----------------|
| 213.12.016  | 16             | 16             | 20             | 28             | 5              | 58             | 24  | 320             |
| 213.12.020  | 20             | 20             | 22             | 34             | 6              | 68             | 30  | 500             |
| 213.12.024  | 25             | 24             | 25             | 38             | 8              | 78             | 36  | 1000            |
| 213.12.030  | 32             | 30             | 32             | 45             | 10             | 95             | 41  | 1500            |
| 213.12.036  | 40             | 36             | 40             | 56             | 12             | 118            | 50  | 2500            |

SW = Düzlemler arası genişlik



2130.03.

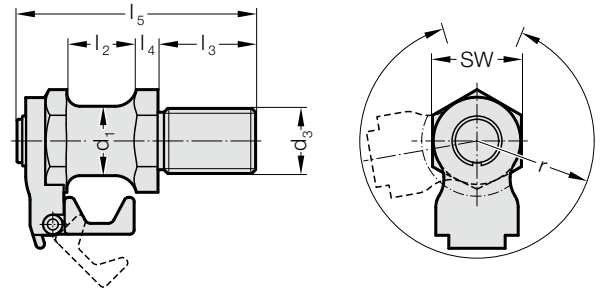

#### Not:

Kablo güvenliği cihazını açmak için, 2130.00.03.01 kodlu anahtarı kullanın (ayrı sipariş edilir).

#### 2130.03. Kaldırma vidalı kablo koruma ekipmanlı

| Sipariş No. | d <sub>1</sub> | d <sub>3</sub> | l <sub>2</sub> | l <sub>3</sub> | l <sub>4</sub> | l <sub>5</sub> | SW | r  | Kapasitesi [kg] |
|-------------|----------------|----------------|----------------|----------------|----------------|----------------|----|----|-----------------|
| 2130.03.020 | 20             | M20            | 22             | 34             | 6.5            | 80             | 30 | 38 | 500             |
| 2130.03.024 | 25             | M24            | 25             | 38             | 8              | 92.5           | 36 | 42 | 1000            |
| 2130.03.030 | 32             | M30            | 32             | 45             | 10             | 109.5          | 41 | 50 | 1500            |
| 2130.03.036 | 40             | M36            | 40             | 56             | 12             | 131.5          | 50 | 57 | 2500            |