


VIS DE RÉGLAGE ECROU HEXAGONAL DIN 6330 B

2140.02.

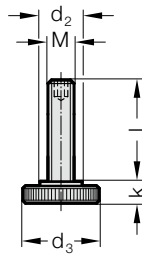


2140.02. Vis de réglage

N° de commande	M	d ₂	d ₃	k	l
2140.02.10	10	16	30	8	39
2140.02.12	12	20	36	10	48
2140.02.16	16	25	42	13	55
2140.02.20	20	25	50	16	69
2140.02.24	24	34	60	20	87

Matière :

traité, classe de résistance mécanique 8.8

2140.32.

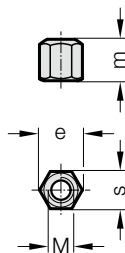

2140.32. Ecrou hexagonal DIN 6330 B

N° de commande	M	e	m	s
2140.32.08	M8	15	12	13
2140.32.10	M10	18,4	15	16
2140.32.12	M12	20,7	18	18
2140.32.14	M14	24,2	21	21
2140.32.16	M16	27,7	24	24
2140.32.18	M18	31,2	27	27
2140.32.20	M20	34,6	30	30
2140.32.22	M22	39,2	33	34
2140.32.24	M24	41,5	36	36
2140.32.30	M30	53,1	45	46

Matière :

traité, classe de résistance mécanique 10.9

Remarque :

Utiliser rondelles selon DIN 6340.