


# STELLSCHRAUBE SECHSKANTMUTTER DIN 6330 B

2140.02.

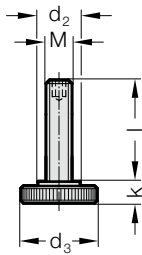


## 2140.02. Stellschraube

Bestell-Nummer	M	d <sub>2</sub>	d <sub>3</sub>	k	l
2140.02.10	10	16	30	8	39
2140.02.12	12	20	36	10	48
2140.02.16	16	25	42	13	55
2140.02.20	20	25	50	16	69
2140.02.24	24	34	60	20	87

### Werkstoff:

vergütet, Festigkeitsklasse 8.8

2140.32.

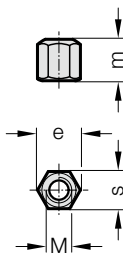

## 2140.32. Sechskantmutter DIN 6330 B

Bestell-Nummer	M	e	m	s
2140.32.08	M8	15	12	13
2140.32.10	M10	18,4	15	16
2140.32.12	M12	20,7	18	18
2140.32.14	M14	24,2	21	21
2140.32.16	M16	27,7	24	24
2140.32.18	M18	31,2	27	27
2140.32.20	M20	34,6	30	30
2140.32.22	M22	39,2	33	34
2140.32.24	M24	41,5	36	36
2140.32.30	M30	53,1	45	46

### Werkstoff:

vergütet, Festigkeitsklasse 10.9

### Hinweis:

Scheiben nach DIN 6340 verwenden.