


ŚRUBA USTALAJĄCA NAKRĘTKA SZEŚCIOKĄTNA DIN 6330 B

2140.02.

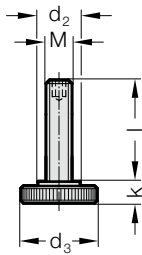


2140.02. Śruba ustalająca

Numer katalogowy	M	d ₂	d ₃	k	l
2140.02.10	10	16	30	8	39
2140.02.12	12	20	36	10	48
2140.02.16	16	25	42	13	55
2140.02.20	20	25	50	16	69
2140.02.24	24	34	60	20	87

Material:

Ulepszony cieplnie, klasa wytrzymałości 8.8

2140.32.

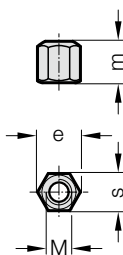

2140.32. Nakrętka sześciokątna DIN 6330 B

Numer katalogowy	M	e	m	s
2140.32.08	M8	15	12	13
2140.32.10	M10	18,4	15	16
2140.32.12	M12	20,7	18	18
2140.32.14	M14	24,2	21	21
2140.32.16	M16	27,7	24	24
2140.32.18	M18	31,2	27	27
2140.32.20	M20	34,6	30	30
2140.32.22	M22	39,2	33	34
2140.32.24	M24	41,5	36	36
2140.32.30	M30	53,1	45	46

Material:

Ulepszony cieplnie, klasa wytrzymałości 10.9

Uwaga:

Stosować podkładki okrągłe wg DIN 6340.