


VIS POUR RAINURE EN T, DIN 787

2140.30.

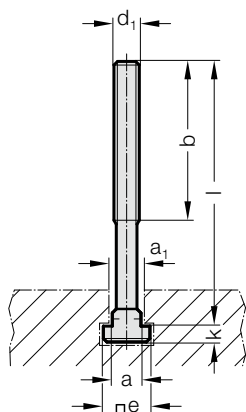

Matière :

traité,
M 8 – M12, classe de résistance mécanique 10.9
M14 – M30, classe de résistance mécanique 8.8

Exécution :

Forgé, filetage roulé, glissière à rainure en T fraisée

2140.30. Vis pour rainure en T, DIN 787

| N° de commande | a ₁ | a | b | d ₁ | e | k | l |
|-------------------|----------------|------|-----|----------------|----|----|-----|
| 2140.30.08.08.032 | 8 | 7,7 | 22 | 8 | 13 | 6 | 32 |
| 2140.30.08.08.050 | 8 | 7,7 | 35 | 8 | 13 | 6 | 50 |
| 2140.30.08.08.080 | 8 | 7,7 | 50 | 8 | 13 | 6 | 80 |
| 2140.30.10.10.040 | 10 | 9,7 | 30 | 10 | 15 | 6 | 40 |
| 2140.30.10.10.063 | 10 | 9,7 | 45 | 10 | 15 | 6 | 63 |
| 2140.30.10.10.100 | 10 | 9,7 | 60 | 10 | 15 | 6 | 100 |
| 2140.30.12.12.050 | 12 | 11,7 | 35 | 12 | 18 | 7 | 50 |
| 2140.30.12.12.063 | 12 | 11,7 | 40 | 12 | 18 | 7 | 63 |
| 2140.30.12.12.080 | 12 | 11,7 | 55 | 12 | 18 | 7 | 80 |
| 2140.30.12.12.125 | 12 | 11,7 | 75 | 12 | 18 | 7 | 125 |
| 2140.30.12.12.200 | 12 | 11,7 | 120 | 12 | 18 | 7 | 200 |
| 2140.30.12.14.050 | 14 | 13,7 | 35 | 12 | 22 | 8 | 50 |
| 2140.30.12.14.063 | 14 | 13,7 | 45 | 12 | 22 | 8 | 63 |
| 2140.30.12.14.080 | 14 | 13,7 | 55 | 12 | 22 | 8 | 80 |
| 2140.30.12.14.125 | 14 | 13,7 | 75 | 12 | 22 | 8 | 125 |
| 2140.30.12.14.200 | 14 | 13,7 | 120 | 12 | 22 | 8 | 200 |
| 2140.30.14.16.063 | 16 | 15,7 | 45 | 14 | 25 | 9 | 63 |
| 2140.30.14.16.100 | 16 | 15,7 | 65 | 14 | 25 | 9 | 100 |
| 2140.30.14.16.160 | 16 | 15,7 | 125 | 14 | 25 | 9 | 160 |
| 2140.30.14.16.250 | 16 | 15,7 | 150 | 14 | 25 | 9 | 250 |
| 2140.30.16.16.063 | 16 | 15,7 | 45 | 16 | 25 | 9 | 63 |
| 2140.30.16.16.080 | 16 | 15,7 | 55 | 16 | 25 | 9 | 80 |
| 2140.30.16.16.100 | 16 | 15,7 | 65 | 16 | 25 | 9 | 100 |
| 2140.30.16.16.160 | 16 | 15,7 | 100 | 16 | 25 | 9 | 160 |
| 2140.30.16.16.200 | 16 | 15,7 | 125 | 16 | 25 | 9 | 200 |
| 2140.30.16.16.250 | 16 | 15,7 | 150 | 16 | 25 | 9 | 250 |
| 2140.30.16.18.063 | 18 | 17,7 | 45 | 16 | 28 | 10 | 63 |
| 2140.30.16.18.080 | 18 | 17,7 | 55 | 16 | 28 | 10 | 80 |
| 2140.30.16.18.100 | 18 | 17,7 | 65 | 16 | 28 | 10 | 100 |
| 2140.30.16.18.160 | 18 | 17,7 | 100 | 16 | 28 | 10 | 160 |
| 2140.30.16.18.200 | 18 | 17,7 | 125 | 16 | 28 | 10 | 200 |
| 2140.30.16.18.250 | 18 | 17,7 | 150 | 16 | 28 | 10 | 250 |
| 2140.30.20.20.080 | 20 | 19,7 | 55 | 20 | 32 | 12 | 80 |
| 2140.30.20.20.100 | 20 | 19,7 | 65 | 20 | 32 | 12 | 100 |

| N° de commande | a ₁ | a | b | d ₁ | e | k | l |
|-------------------|----------------|------|-----|----------------|----|----|-----|
| 2140.30.20.20.125 | 20 | 19,7 | 85 | 20 | 32 | 12 | 125 |
| 2140.30.20.20.160 | 20 | 19,7 | 110 | 20 | 32 | 12 | 160 |
| 2140.30.20.20.200 | 20 | 19,7 | 125 | 20 | 32 | 12 | 200 |
| 2140.30.20.20.250 | 20 | 19,7 | 150 | 20 | 32 | 12 | 250 |
| 2140.30.20.20.315 | 20 | 19,7 | 190 | 20 | 32 | 12 | 315 |
| 2140.30.20.22.080 | 22 | 21,7 | 55 | 20 | 35 | 14 | 80 |
| 2140.30.20.22.100 | 22 | 21,7 | 65 | 20 | 35 | 14 | 100 |
| 2140.30.20.22.125 | 22 | 21,7 | 85 | 20 | 35 | 14 | 125 |
| 2140.30.20.22.160 | 22 | 21,7 | 110 | 20 | 35 | 14 | 160 |
| 2140.30.20.22.200 | 22 | 21,7 | 125 | 20 | 35 | 14 | 200 |
| 2140.30.20.22.250 | 22 | 21,7 | 150 | 20 | 35 | 14 | 250 |
| 2140.30.20.22.315 | 22 | 21,7 | 190 | 20 | 35 | 14 | 315 |
| 2140.30.24.24.100 | 24 | 23,7 | 70 | 24 | 40 | 16 | 100 |
| 2140.30.24.24.125 | 24 | 23,7 | 85 | 24 | 40 | 16 | 125 |
| 2140.30.24.24.160 | 24 | 23,7 | 110 | 24 | 40 | 16 | 160 |
| 2140.30.24.24.200 | 24 | 23,7 | 125 | 24 | 40 | 16 | 200 |
| 2140.30.24.24.250 | 24 | 23,7 | 150 | 24 | 40 | 16 | 250 |
| 2140.30.24.24.315 | 24 | 23,7 | 190 | 24 | 40 | 16 | 315 |
| 2140.30.24.24.400 | 24 | 23,7 | 240 | 24 | 40 | 16 | 400 |
| 2140.30.24.28.100 | 28 | 27,7 | 70 | 24 | 44 | 18 | 100 |
| 2140.30.24.28.125 | 28 | 27,7 | 85 | 24 | 44 | 18 | 125 |
| 2140.30.24.28.160 | 28 | 27,7 | 110 | 24 | 44 | 18 | 160 |
| 2140.30.24.28.200 | 28 | 27,7 | 125 | 24 | 44 | 18 | 200 |
| 2140.30.24.28.250 | 28 | 27,7 | 150 | 24 | 44 | 18 | 250 |
| 2140.30.24.28.315 | 28 | 27,7 | 190 | 24 | 44 | 18 | 315 |
| 2140.30.24.28.400 | 28 | 27,7 | 240 | 24 | 44 | 18 | 400 |
| 2140.30.30.36.125 | 36 | 35,6 | 80 | 30 | 54 | 22 | 125 |
| 2140.30.30.36.160 | 36 | 35,6 | 110 | 30 | 54 | 22 | 160 |
| 2140.30.30.36.200 | 36 | 35,6 | 135 | 30 | 54 | 22 | 200 |
| 2140.30.30.36.250 | 36 | 35,6 | 150 | 30 | 54 | 22 | 250 |
| 2140.30.30.36.315 | 36 | 35,6 | 200 | 30 | 54 | 22 | 315 |
| 2140.30.30.36.500 | 36 | 35,6 | 300 | 30 | 54 | 22 | 500 |