


# HEXAGON SOCKET COUNTERSUNK HEAD CAP SCREW, ISO 10642 - STRENGTH CLASS 8.8



2192.30.

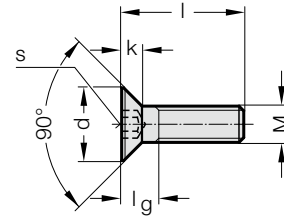

## 2192.30. Hexagon socket countersunk head cap screw, ISO 10642 - Strength class 8.8

Order No	M	l	l <sub>g</sub>	d	k	s
2192.30.03.006	M3	6	3.2	6	1.7	2
2192.30.03.008	M3	8	3.2	6	1.7	2
2192.30.03.010	M3	10	3.2	6	1.7	2
2192.30.04.008	M4	8	4.4	8	2.3	2.5
2192.30.05.010	M5	10	5.2	10	2.8	3
2192.30.05.012	M5	12	5.2	10	2.8	3
2192.30.05.016	M5	16	5.2	10	2.8	3
2192.30.05.020	M5	20	5.2	10	2.8	3
2192.30.05.025	M5	25	5.2	10	2.8	3
2192.30.05.030	M5	30	5.2	10	2.8	3
2192.30.06.010	M6	10	6.3	12	3.3	4
2192.30.06.012	M6	12	6.3	12	3.3	4
2192.30.06.016	M6	16	6.3	12	3.3	4
2192.30.06.020	M6	20	6.3	12	3.3	4
2192.30.06.025	M6	25	6.3	12	3.3	4
2192.30.06.030	M6	30	6.3	12	3.3	4
2192.30.08.010	M8	10	5.6	16	4.4	5
2192.30.08.016	M8	16	8.2	16	4.4	5
2192.30.08.020	M8	20	8.2	16	4.4	5
2192.30.08.025	M8	25	8.2	16	4.4	5
2192.30.08.030	M8	30	8.2	16	4.4	5
2192.30.10.020	M10	20	10	20	5.5	6
2192.30.10.025	M10	25	10	20	5.5	6
2192.30.10.040	M10	40	10	20	5.5	6
2192.30.12.030	M12	30	11.8	24	6.5	8
2192.30.12.050	M12	50	11.8	24	6.5	8