


带内螺纹的圆柱销, DIN EN ISO 8735

2361.1.

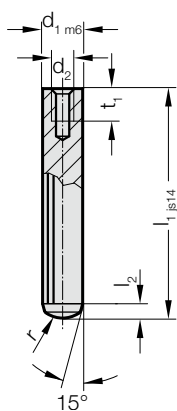

材料:
 钢
 硬度 60 ± 2 HRC
 结构:
 渗碳硬化, 精磨。

2361.1. 带内螺纹的圆柱销, DIN EN ISO 8735

| d ₁ | d ₂ | t ₁ | l ₂ | r | l ₁ | 8 | 10 | 12 | 14 | 16 | 18 | 20 | 22 | 24 | 26 | 28 | 30 | 32 | 36 | 40 | 45 | 50 | 55 | 60 | 70 | 80 | 90 | 100 | 120 |
|----------------|----------------|----------------|----------------|----|----------------|---|----|----|----|----|----|----|----|----|----|----|----|----|----|----|----|----|----|----|----|----|----|-----|-----|
| 4 | M2,5 | 4.5 | 1.3 | 4 | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 5 | M3 | 5 | 1.7 | 5 | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 6 | M4 | 6 | 2.1 | 6 | | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 8 | M5 | 8 | 2.6 | 8 | | | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 10 | M6 | 10 | 3 | 10 | | | | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 12 | M6 | 10 | 3.8 | 12 | | | | | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 14 | M8 | 12 | 4 | 14 | | | | | | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 16 | M8 | 12 | 4.7 | 16 | | | | | | | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |
| 20 | M10 | 16 | 6 | 20 | | | | | | | | | | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● | ● |

订购示例:

| | | |
|---------------------------|---------|-------------------|
| 带内螺纹的圆柱销, DIN EN ISO 8735 | = | 2361.1. |
| 直径 d ₁ | 10 mm = | 1000. |
| 长度 l ₁ | 16 mm = | 016 |
| 订购编号 | = | 2361.1. 1000. 016 |