



# 弹簧座 DIN ISO 10069-2 止推垫圈

## 2441.3.

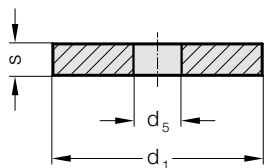

### 安装示例

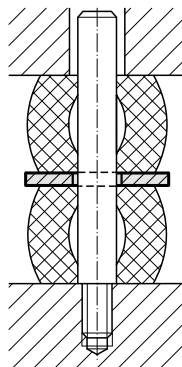

## 2441.3. 弹簧座 DIN ISO 10069-2


弹簧 Ø	16	20	25	32	40	50	63	80	100	125
d <sub>1</sub>	20	25	30	40	50	60	80	100	120	150
d <sub>5</sub>	6.5	8.5	10.5	13.5	13.5	16.5	16.5	20.5	20.5	26
s	4	4	5	5	5	6	6	8	8	8

材料:  
黄铜


### 订购示例:

弹簧座 DIN ISO 10069-2 = 2441.3.  
 弹簧直径 弹簧 Ø 50 mm = 050  
 订购编号 = 2441.3.050

## 244.4.

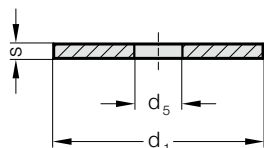

### 安装示例

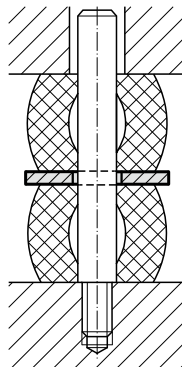

## 244.4. 止推垫圈

弹簧 Ø	16	20	25	32	40	50	63	80	100	125
d <sub>1</sub>	20	26	32	40	50	60	80	100	120	150
d <sub>5</sub>	6.5	8.5	10.5	13.5	13.5	16.5	16.5	20.5	20.5	26
s	1	1.5	2	2.5	2.5	3	3	4	4	5

材料:  
St 37

### 订购示例:

止推垫圈 = 244.4.  
 弹簧直径 弹簧 Ø 50 mm = 050  
 订购编号 = 244.4.050