



## DISCO DE MUELLE DIN ISO 10069-2

### DISCO DE APOYO

2441.3.

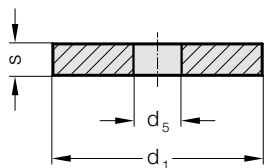

Ejemplo de montaje

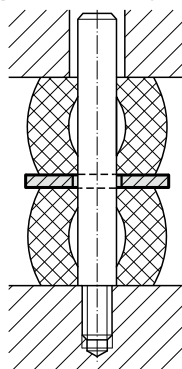

2441.3. Disco de muelle DIN ISO 10069-2

ø muelle	16	20	25	32	40	50	63	80	100	125
d <sub>1</sub>	20	25	30	40	50	60	80	100	120	150
d <sub>5</sub>	6,5	8,5	10,5	13,5	13,5	16,5	16,5	20,5	20,5	26
s	4	4	5	5	5	6	6	8	8	8


Material:

Latón


Ejemplo de código:

Disco de muelle DIN ISO 10069-2	=	2441.3.
Diámetro de muelle ø muelle	50 mm =	050
Código	=	2441.3. 050

244.4.

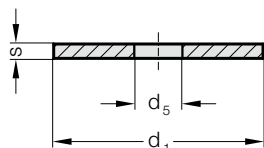

Ejemplo de montaje

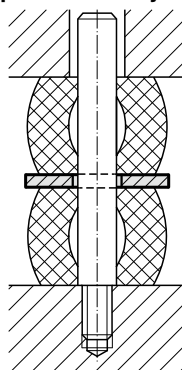

244.4. Disco de apoyo

ø muelle	16	20	25	32	40	50	63	80	100	125
d <sub>1</sub>	20	26	32	40	50	60	80	100	120	150
d <sub>5</sub>	6,5	8,5	10,5	13,5	13,5	16,5	16,5	20,5	20,5	26
s	1	1,5	2	2,5	2,5	3	3	4	4	5

Material:

St 37

Ejemplo de código:

Disco de apoyo	=	244.4.
Diámetro de muelle ø muelle	50 mm =	050
Código	=	244.4. 050