


带有组合块的举升装置符合BMW标准

2478.20.15.20.

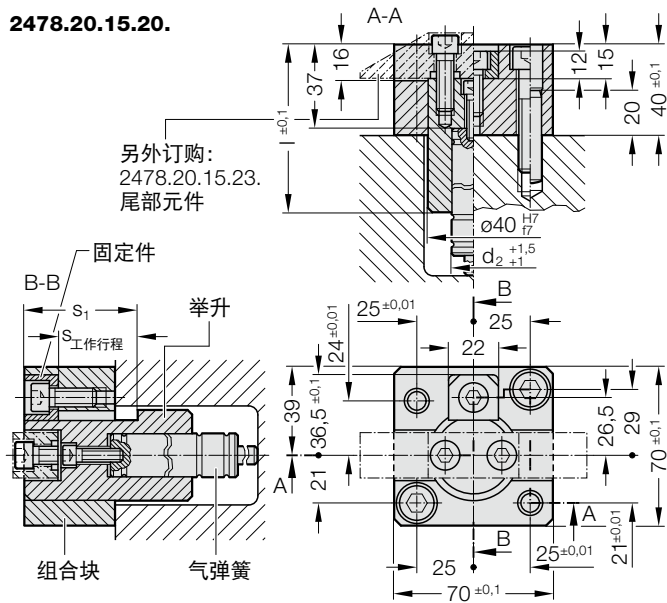

材料:
钢

结构:
带有组合块的举升装置组成由:


- 组合块
- 举升
- 固定件
- 气弹簧 2482.74.00090. 或 2480.21.00200.
- 螺栓根据 ISO 4762
M6×20 (1x), M8×20 (1x), M8×25 (2x), M10×45 (2x)
- 圆柱销根据 ISO 8735 $\phi 10 \times 40$ (2x)

说明:
另外订购 (见安装实例)

- 2478.20.15.23.: 举升导向
- 2478.20.15.24.: 托套

以較低的彈簧力可應要求提供氣彈簧。

安装示例

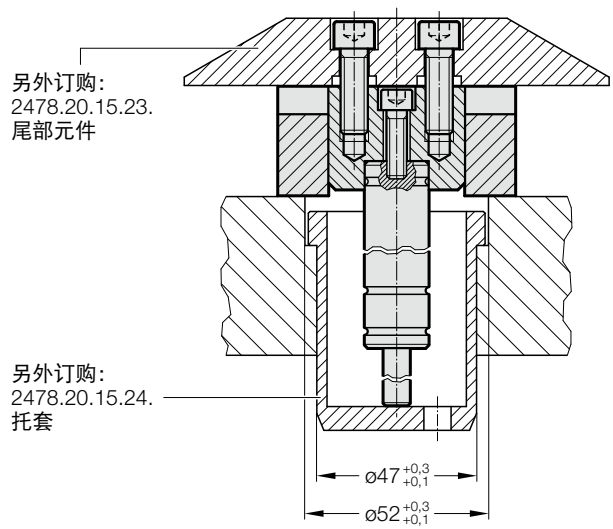

2478.20.15.20. 带有组合块的举升装置符合BMW标准

订购编号	d_2	l	S _{工作行程}	S ₁	氮气弹簧
2478.20.15.20.14.009	19	49	9	25	2482.74.00090.010.2
2478.20.15.20.24.009	25	49	9	25	2480.21.00200.010
2478.20.15.20.14.014	19	53.5	13.5	29.5	2482.74.00090.015.2
2478.20.15.20.24.014	25	53.5	13.5	29.5	2480.21.00200.015
2478.20.15.20.14.023	19	62.5	22.5	38.5	2482.74.00090.025.2
2478.20.15.20.24.023	25	62.5	22.5	38.5	2480.21.00200.025
2478.20.15.20.14.034	19	74	34	50	2482.74.00090.038.2
2478.20.15.20.24.034	25	74	34	50	2480.21.00200.038
2478.20.15.20.14.045	19	85	45	61	2482.74.00090.050.2
2478.20.15.20.24.045	25	85	45	61	2480.21.00200.050
2478.20.15.20.14.059	19	98.5	58.5	74.5	2482.74.00090.063.2
2478.20.15.20.24.059	25	98.5	58.5	74.5	2480.21.00200.063
2478.20.15.20.14.075	19	115	75	91	2482.74.00090.080.2
2478.20.15.20.24.075	25	115	75	91	2480.21.00200.080
2478.20.15.20.14.095	19	135	95	111	2482.74.00090.100.2
2478.20.15.20.24.095	25	135	95	111	2480.21.00200.100
2478.20.15.20.14.120	19	160	120	136	2482.74.00090.125.2
2478.20.15.20.24.120	25	160	120	136	2480.21.00200.125