

GAS SPRING ACCESSORIES

CONNECTOR SYSTEM, 24° CONUS MICRO

2480.00.27.01

M8x1 hose connector

Order example:

Shortest factory length:


- 90 mm excl. bend protection
- 150 mm bend protection on one side
- 300 mm bend protection on both sides
- Minimum bending radius: R20 mm

*Measuring hose available in the following lengths:

- 5 mm step range ≤ 1000 mm
- 10 mm step range > 1000 mm
- 100 mm step range > 4000 mm
- 500 mm step range > 6000 mm

2480.00.27.01.

Connection hose, 24° conus micro, straight on both sides (connection hose, sealing cone with union nut and O ring)

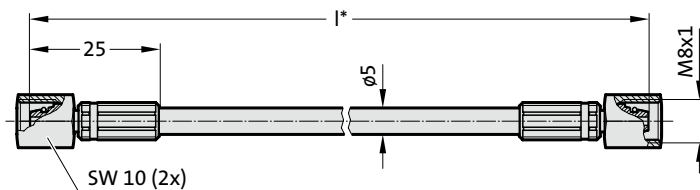


2480.00.27.01.....1

Antikink spiral, at one end



2480.00.27.01.....2

 Antikink spiral, at both ends




Ordering Code (example):

M8x1 hose connector	= 2480.00.27.01.	M8x1 hose connector	= 2480.00.27.01.
l = 90 mm	= 0090	l = 90 mm	= 0090.
Order No	= 2480.00.27.01. 0090	Bend protection on one side	= 1
		Order No	= 2480.00.27.01. 0090. 1

2480.00.23.12.01

Hose clamp
for gauging hose DN2 (Ø5 mm)

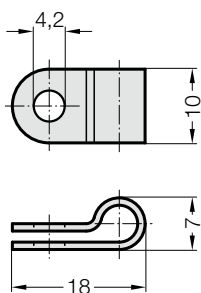

Material:

 
Polyamide

Note:

Supplied without screws

2192.50.04.012

Self-tapping screw DIN 7516
M4x12



Note:

self-tapping
Diameter of hole for self-tapping screw = 3.6 mm

2480.00.23.13.

Anti-scuff spiral
for subsequent installation over hoses and tubing



Order No.	l [m]
2480.00.23.13.0001	1
2480.00.23.13.0002	2
2480.00.23.13.0005	5
2480.00.23.13.0010	10

Inner ø 7 mm
For hose external ø max. 5-11 mm
Temperature range -30°C up to +100°C

Description:

The anti-scuff spiral is used to protect against abrasion, is resistant to air, water, oil, hydraulic fluids petrol and other liquids.

Material:

Polyamide