


冲头, 类似与DIN 9844, A 型

270.

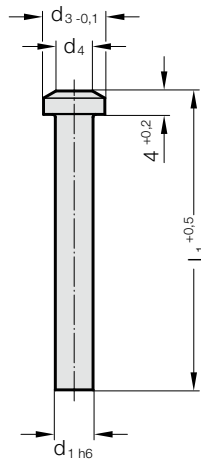

$$d_4 = \varnothing^{+0,5}$$



材料:
硬质合金
订货号 270.9.

结构:
凸模柄部精磨。
顶部: 钢制, 与下端是钎焊。

欲订购其它长度和直径时请向我 公司咨询!

270. 冲头, 类似与DIN 9844, A 型

分级					71	90	112
d_1	d_1	d_3	r	l_1			
1	0.1	3.6	0.2		●	●	●
2.3	0.1	4	0.2		●	●	●
2.6	0.1	4.5	0.3		●	●	●
2.9	0.1	5	0.3		●	●	●
3.3	0.1	6	0.3		●	●	●
3.6	0.1	7	0.3		●	●	●
4.1	0.1	8	0.5		●	●	●
4.6	0.1	8.5	0.5		●	●	●
5.1	0.1	9	0.5		●	●	●
5.5	0.1	9.5	0.5		●	●	●
6	0.1	10	0.5		●	●	●
6.5	0.5	10.8	0.7		●	●	●
7.5	0.5	12	0.7		●	●	●
8.5	0.5	13	0.7		●	●	●
9.5	0.5	14.5	0.7		●	●	●
10.5	0.5	16	1		●	●	●
11.5	0.5	18	1		●	●	●
13	0.5	20	1		●	●	●
15	0.5	22	1		●	●	●

订购示例:

冲头, 类似与DIN 9844, A 型 = 270.9.
 轴径 d_1 4.7 mm = 0470.
 长度 l_1 71 mm = 071
 订购编号 = 270.9. 0470. 071