

精密扁钢和精密方钢, ~DIN 59350

2922.1730.




材料:

1.1730 / C45U

非合金工具钢

结构:

厚度已精磨, 宽度已打磨或铣削, 长度已加工

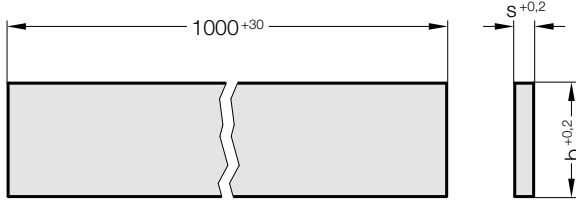

2922.1730. 精密扁钢和精密方钢, ~DIN 59350

s	4	5	6	8	10	12	15	16	20	25	30	32	40	50	60	63	70	80	100	120	150	
b																						
10					●																	
12						●																
15							●															
16								●														
20	●	●	●	●	●	●	●	●	●													
25	●	●	●	●	●	●	●	●	●	●												
30	●	●	●	●	●	●	●	●	●	●	●											
32	●	●	●	●	●	●	●	●	●	●	●	●										
40	●	●	●	●	●	●	●	●	●	●	●	●	●									
50	●	●	●	●	●	●	●	●	●	●	●	●	●	●								
60	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●							
63			●	●	●	●	●	●	●	●	●	●	●	●	●	●						
70			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●					
80	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●				
90	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
100	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
120			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	
125	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
140			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
150	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
160			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
180			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
200			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
250			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
300			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
350			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
400	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
450																						
500																						

订购示例:

精密扁钢和精密方钢, ~DIN 59350	=	2922.1730.
宽 B	90 mm =	090.
厚度 S	4 mm =	004.
长度 L	1000 mm =	1000
订购编号	=	2922.1730. 090. 004. 1000