

ACIER PLAT DE PRÉCISION ET ACIER POLYÉDRIQUE DE PRÉCISION, ~DIN 59350

2922.1730.



Nous proposons une
qualité originale
BÖHLER


Matière :

1.1730 / C45U

Acier à outils non allié

Exécution :

Epaisseur poncée avec précision, largeur poncée ou fraisée, longueur usinée

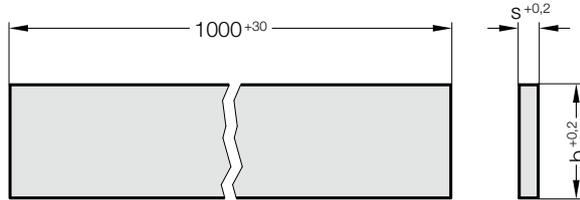

2922.1730. Acier plat de précision et acier polyédrique de précision, ~DIN 59350

s	4	5	6	8	10	12	15	16	20	25	30	32	40	50	60	63	70	80	100	120	150	
b																						
10					●																	
12						●																
15							●															
16								●														
20	●	●	●	●	●	●	●	●	●													
25	●	●	●	●	●	●	●	●	●	●												
30	●	●	●	●	●	●	●	●	●	●	●											
32	●	●	●	●	●	●	●	●	●	●	●	●										
40	●	●	●	●	●	●	●	●	●	●	●	●	●									
50	●	●	●	●	●	●	●	●	●	●	●	●	●	●								
60	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●							
63			●	●	●	●	●	●	●	●	●	●	●	●	●	●						
70		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●					
80	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●				
90	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
100	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
120			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	
125	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
140			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
150	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
160			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
180			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
200			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
250			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
300			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
350			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
400	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
450																						
500																						

Exemple de commande :

Acier plat de précision et acier polyédrique de précision, ~DIN 59350	=	2922.1730.
Largeur B	90 mm =	090.
Epaisseur S	4 mm =	004.
Longueur L	1000 mm =	1000
N° de commande	=	2922.1730. 090. 004. 1000