

符合DIN 59350带有加工余量的精密扁钢和精密方钢

2923.2312.




我们为您提供
BÖHLER
原装质量

材料:

以 900-1050 N/mm² 对 1.2312 / 40 CrMnMoS 8-6
抗腐蚀塑料模具钢进行调质处理

结构:

厚度已精磨, 宽度已打磨或铣削, 长度已加工

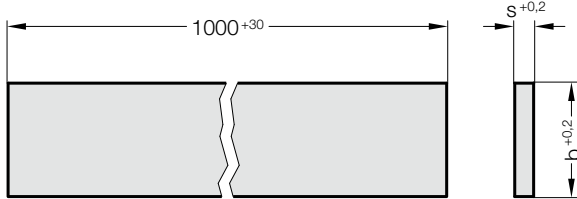

2923.2312. 符合DIN 59350带有加工余量的精密扁钢和精密方钢

s	4.2	5.2	6.2	8.2	10.4	12.4	15.4	16.4	20.4	25.4	30.4	32.4	40.4	50.4	60.4	70.4	80.4	90.4	100.4	
b																				
12.4						●														
15.4							●													
16.4								●												
20.3				●	●	●	●													
20.4									●											
25.3				●	●	●	●	●	●											
25.4										●										
30.3				●	●	●	●	●	●	●										
30.4											●									
32.3					●	●		●	●											
32.4												●								
40.3	●	●	●	●	●	●	●	●	●	●	●									
40.4													●							
50.3	●	●	●	●	●	●	●	●	●	●	●	●	●							
50.4														●						
60.3	●	●	●	●	●	●	●	●	●	●	●	●	●	●						
60.4															●					
63.3	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●					
70.3	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●				
70.4																●				
80.3	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
80.4																		●		
100.3	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
100.4																				●
125.3				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	
150.3				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
200.3				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
220.3					●	●		●	●	●	●	●	●	●	●	●	●	●	●	●
250.3					●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
300.3					●	●		●	●	●	●	●	●	●	●	●	●	●	●	●

订购示例:

符合DIN 59350带有加工余量的精密扁钢和精密方钢	=	2923.2312.
宽 B	30.3 mm =	030.
厚度 S	8.2 mm =	008.
长度 L	1000 mm =	1000
订购编号	=	2923.2312. 030. 008. 1000