

İÇİN İŞLENME PAYLI HASSAS DÜZ VE KARE ÇELİK BAR, DIN 59350

2923.2312.




Malzeme:

1.2312 / 40 CrMnMoS 8-6

Plastik kalpları için çelik, 900-1050 N/mm² ye sertleştirilmiş

Yürütme:

Kalınlık kesinlik alanı, geniş yüzeyli ya da işlenmiş, uzunluğu işlenmiş

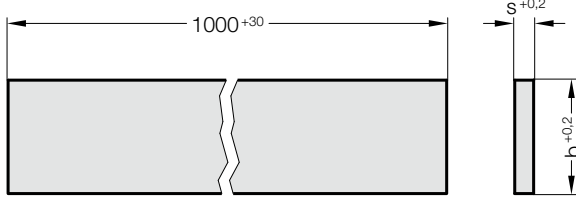

2923.2312. İçin işlenme paylı hassas düz ve kare çelik bar, DIN 59350

s	4,2	5,2	6,2	8,2	10,4	12,4	15,4	16,4	20,4	25,4	30,4	32,4	40,4	50,4	60,4	70,4	80,4	90,4	100,4
b																			
12,4						•													
15,4							•												
16,4								•											
20,3				•	•	•	•												
20,4									•										
25,3				•	•	•	•	•	•										
25,4										•									
30,3				•	•	•	•	•	•	•									
30,4											•								
32,3					•	•		•	•										
32,4												•							
40,3	•	•	•	•	•	•	•	•	•	•	•								
40,4													•						
50,3	•	•	•	•	•	•	•	•	•	•	•	•	•						
50,4														•					
60,3	•	•	•	•	•	•	•	•	•	•	•	•	•	•					
60,4															•				
63,3	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•				
70,3	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•			
70,4																•			
80,3	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•		
80,4																	•		
100,3	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	
100,4																			•
125,3				•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	
150,3				•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•
200,3				•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•
220,3					•	•		•	•	•	•	•	•	•	•	•	•	•	•
250,3					•	•	•		•	•	•	•	•	•	•	•	•	•	•
300,3					•	•			•	•	•	•	•	•	•	•	•	•	•

Siparis Kodu (örnek):

İçin işlenme paylı hassas düz ve kare çelik bar, DIN 59350	=	2923.2312.
Genişlik B	30.3 mm	= 030.
Kalınlık S	8.2 mm	= 008.
Uzunluk L	1000 mm	= 1000
Siparis No		= 2923.2312. 030. 008. 1000