

符合DIN 59350带有加工余量的精密扁钢和精密方钢

材料:
1.2379 / X 155 CrVMo 12-1
冷锻模钢


2923.2379.



我们为您提供
BÖHLER
原装质量

结构:
厚度已精磨, 宽度已打磨或铣削, 长度已加工

说明:
● = 适用于 500 mm 和 1000 mm 长度
○ = 仅适用于 500 mm 长度
■ = 仅适用于 1000 mm 长度

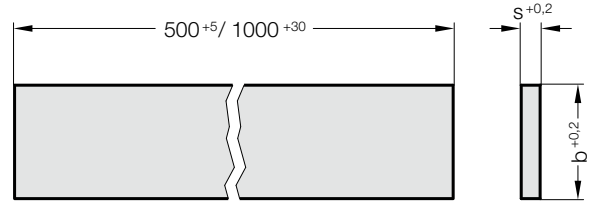

2923.2379. 符合DIN 59350带有加工余量的精密扁钢和精密方钢

s	2.2	3.2	4.2	5.2	6.2	8.2	10.4	12.4	15.4	16.4	20.4	25.4	30.4	32.4	40.4	50.4	60.4	63.4	70.4	80.4	100.4	120.4	150.4	
b																								
6.2						○																		
8.2						●																		
10.3	●	●	●	●	●	●																		
10.4							●																	
12.4								●																
15.3	●	●	●	●	●	●	●	●	■															
15.4									●															
16.4										■														
20.3	●	●	●	●	●	●	●	●	●	■														
20.4											●													
25.3	●	●	●	●	●	●	●	●	●	■	●													
25.4												●												
30.3	●	●	●	●	●	●	●	●	●	■	●	●												
30.4													●											
32.3							■	■	■		■	■	■											
32.4														■										
40.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■										
40.4																								
50.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■										
50.4																								
60.3	●	●	●	●	●	●	●	●	●		●	●	●		●	●								
60.4																								
63.3							■	■	■		■	■	■		■	■	■							
63.4																								
70.3	■	■	■	■	■	■	■	■	■	■	■	■	■	■	■	■	■							
70.4																								
80.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■	●	●	■							
80.4																								
90.3							■	■	■		■	■	■	■	■	■	■							
100.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■	●	●	■							
100.4																								
120.4																								
125.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■	●	●	■			■	■	■		
150.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■	●	●	■			■	■	■		
150.4																								
160.3							■	■	■	■	■	■	■	■	■	■	■							
200.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■	●	●	■			■	■	■		
250.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■	●	●	■							
300.3	●	●	●	●	●	●	●	●	●	■	●	●	●	■	●	●	■							
350.3										■	■	■	■	■	■	■								
400.3										■	■	■	■	■	■									

订购示例:

符合DIN 59350带有加工余量的精密扁钢和精密方钢	=	2923.2379.
宽 B	15.3 mm =	015.
厚度 S	2.2 mm =	002.
长度 L	500 mm =	0500
订购编号	=	2923.2379. 015.002.0500