


# SÜRTÜNME PLAKASI, KÜÇÜK ÖLÇÜLERDE, BRONZ KENDİNDEN YAĞLAMALI




2960.72.




A

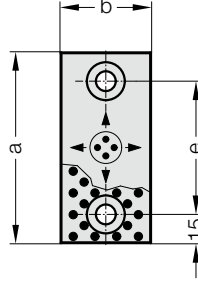


B

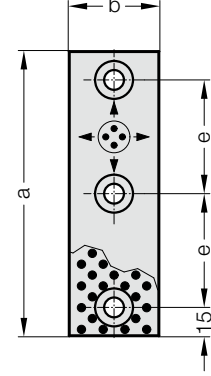


2960.72.

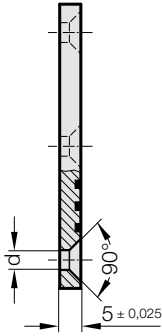

C

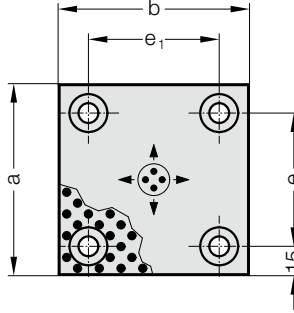

D

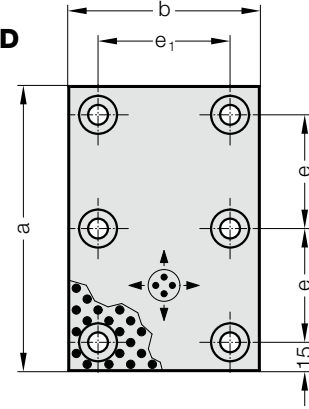

## Malzeme:

Bronz Kendinden Yağlamalı

## Not:

Civatalar dahil değildir.

## Sabitleme:

Havşa başlı vida kullanın  
DIN 7991/ISO 10642.

## 2960.72. Sürtünme Plakası, Küçük Ölçülerde, Bronz Kendinden Yağlamalı

Sipariş No.	Şekil	b	a	e	e <sub>1</sub>	d	Vida Deliği adedi
2960.72.018.050	A	18	50	20	-	6,5	2
2960.72.018.075	A	18	75	45	-	6,5	2
2960.72.018.100	A	18	100	70	-	6,5	2
2960.72.018.150	B	18	150	60	-	6,5	3
2960.72.028.050	A	28	50	20	-	9	2
2960.72.028.075	A	28	75	45	-	9	2
2960.72.028.100	A	28	100	70	-	9	2
2960.72.028.150	B	28	150	60	-	9	3
2960.72.038.050	A	38	50	20	-	9	2
2960.72.038.075	A	38	75	45	-	9	2
2960.72.038.100	A	38	100	70	-	9	2
2960.72.038.150	B	38	150	60	-	9	3
2960.72.048.075	A	48	75	45	-	9	2
2960.72.048.100	A	48	100	70	-	9	2
2960.72.048.125	A	48	125	95	-	9	2
2960.72.048.150	B	48	150	60	-	9	3
2960.72.075.075	C	75	75	45	45	9	4
2960.72.075.100	C	75	100	70	45	9	4
2960.72.075.125	C	75	125	95	45	9	4
2960.72.075.150	D	75	150	60	45	9	6
2960.72.100.100	C	100	100	70	70	9	4
2960.72.100.125	C	100	125	95	70	9	4
2960.72.100.150	D	100	150	60	70	9	6