

# SLIDING PAD, BRONZE WITH SOLID LUBRICANT, AFNOR/ISO 9183-2



**Material:**

Bronze with solid lubricant, oilless lubricating










**Note:**

Screws are not included.


**Fixing:**

Use socket cap screws DIN EN ISO 4762 M10.

2960.74.

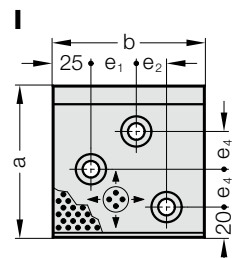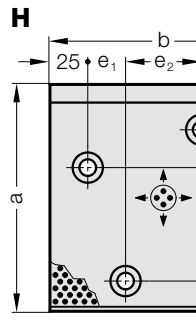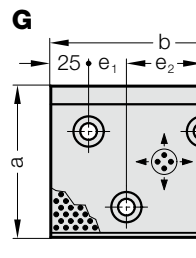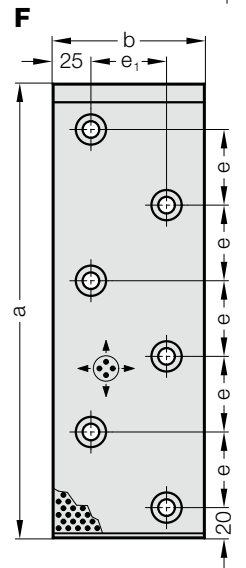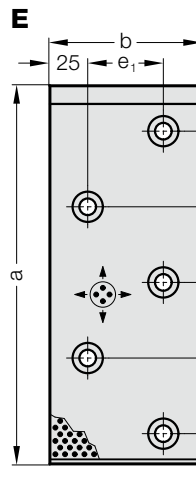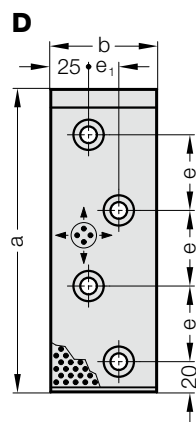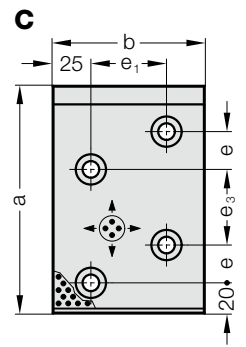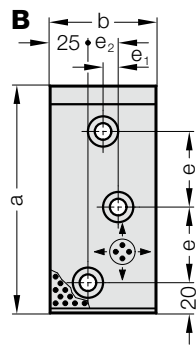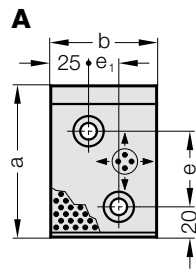

2960.74.

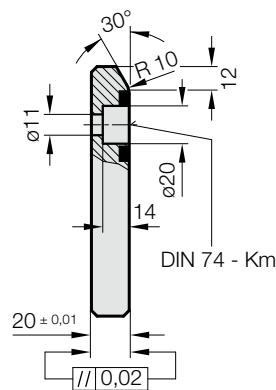

## SLIDING PAD, BRONZE WITH SOLID LUBRICANT, AFNOR/ISO 9183-2

---

### 2960.74. Sliding pad, Bronze with solid lubricant, AFNOR/ISO 9183-2

Order No	Shape	b	a	e	e <sub>1</sub>	e <sub>2</sub>	e <sub>3</sub>	e <sub>4</sub>	Number of screw holes
2960.74.070.100	A	70	100	50	20	-	-	-	2
2960.74.070.150	B	70	150	50	10	20	-	-	3
2960.74.070.200	D	70	200	50	20	-	-	-	4
2960.74.100.100	I	100	100		30	20	-	25	3
2960.74.100.150	C	100	150	25	50	-	50	-	4
2960.74.100.200	D	100	200	50	50	-	-	-	4
2960.74.100.250	E	100	250	50	50	-	-	-	5
2960.74.100.300	F	100	300	50	50	-	-	-	6
2960.74.150.100	G	150	100		25	50	50	-	4
2960.74.150.150	H	150	150		25	50	-	-	4
2960.74.150.200	D	150	200	50	100	-	-	-	4
2960.74.150.250	E	150	250	50	100	-	-	-	5
2960.74.150.300	F	150	300	50	100	-	-	-	6
2960.74.200.100	G	200	100		50	50	50	-	4