


# SÜRTÜNME PLAKASI, BRONZ KENDİNDEN YAĞLAMALI




2960.76.


2960.76.

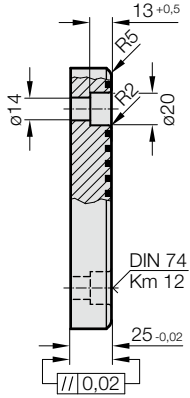

A

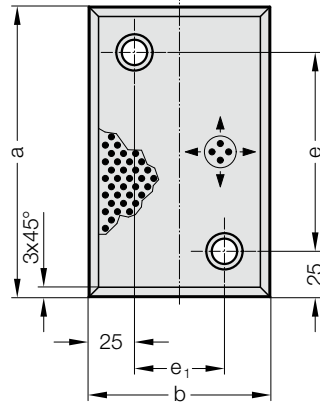

B

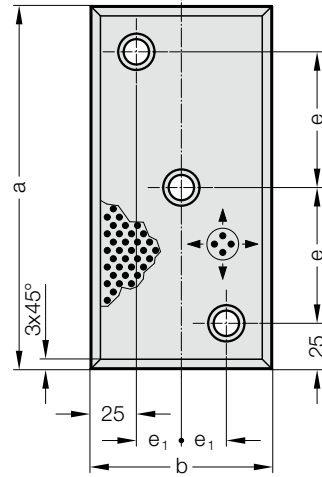

## Malzeme:

Bronz Kendinden Yağlamalı

## Not:

Civatalar dahil değildir.

## Sabitleme:

Soket başlı vida kullanınız  
DIN EN ISO 4762 M12.

## 2960.76. Sürtünme Plakası, Bronz Kendinden Yağlamalı

Sipariş No.	Şekil	b	a	e	e <sub>1</sub>	Vida Deliği adedi
2960.76.080.100	A	80	100	50	30	2
2960.76.080.125	A	80	125	75	30	2
2960.76.080.160	A	80	160	110	30	2
2960.76.080.200	B	80	200	75	15	3
2960.76.100.125	A	100	125	75	50	2
2960.76.100.160	A	100	160	110	50	2
2960.76.100.200	B	100	200	75	25	3
2960.76.125.125	A	125	125	75	75	2