


## 带有四个滑动表面的导向板，带固态润滑剂的青铜

### 2962.74.

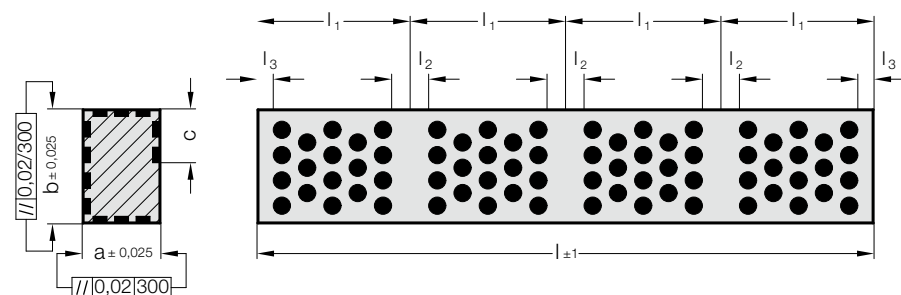

### 材料:

带固态润滑剂的铜, 易维护

### 2962.74. 带有四个滑动表面的导向板，带固态润滑剂的青铜

订购编号	a	b	c	l	l <sub>1</sub>	l <sub>2</sub>	l <sub>3</sub>
2962.74.015.010.075	10.3	15.3	6	75	25	6	3
2962.74.015.010.100	10.3	15.3	6	100	25	6	3
2962.74.015.010.125	10.3	15.3	6	125	25	6	3
2962.74.015.010.150	10.3	15.3	6	150	25	6	3
2962.74.015.010.175	10.3	15.3	6	175	25	6	3
2962.74.015.010.200	10.3	15.3	6	200	25	6	3
2962.74.015.010.225	10.3	15.3	6	225	25	6	3
2962.74.015.010.250	10.3	15.3	6	250	25	6	3
2962.74.015.010.275	10.3	15.3	6	275	25	6	3
2962.74.015.010.300	10.3	15.3	6	300	25	6	3
2962.74.025.015.105	15.3	25.3	8	105	35	8	4
2962.74.025.015.140	15.3	25.3	8	140	35	8	4
2962.74.025.015.175	15.3	25.3	8	175	35	8	4
2962.74.025.015.210	15.3	25.3	8	210	35	8	4
2962.74.025.015.245	15.3	25.3	8	245	35	8	4
2962.74.025.015.280	15.3	25.3	8	280	35	8	4
2962.74.025.015.315	15.3	25.3	8	315	35	8	4
2962.74.025.015.350	15.3	25.3	8	350	35	8	4
2962.74.025.015.385	15.3	25.3	8	385	35	8	4
2962.74.025.015.420	15.3	25.3	8	420	35	8	4
2962.74.025.015.455	15.3	25.3	8	455	35	8	4
2962.74.025.015.490	15.3	25.3	8	490	35	8	4
2962.74.035.025.135	25.3	35.3	12	135	45	10	5
2962.74.035.025.180	25.3	35.3	12	180	45	10	5
2962.74.035.025.225	25.3	35.3	12	225	45	10	5
2962.74.035.025.270	25.3	35.3	12	270	45	10	5
2962.74.035.025.315	25.3	35.3	12	315	45	10	5
2962.74.035.025.360	25.3	35.3	12	360	45	10	5
2962.74.035.025.405	25.3	35.3	12	405	45	10	5
2962.74.035.025.450	25.3	35.3	12	450	45	10	5
2962.74.035.025.495	25.3	35.3	12	495	45	10	5
2962.74.045.035.165	35.3	45.3	16	165	55	12	6
2962.74.045.035.220	35.3	45.3	16	220	55	12	6
2962.74.045.035.275	35.3	45.3	16	275	55	12	6
2962.74.045.035.330	35.3	45.3	16	330	55	12	6
2962.74.045.035.385	35.3	45.3	16	385	55	12	6
2962.74.045.035.440	35.3	45.3	16	440	55	12	6
2962.74.045.035.495	35.3	45.3	16	495	55	12	6