


# ELEMENTO DI SCORRIMENTO ANGOLARE, BRONZO CON INSERTI DI LUBRIFICANTE SOLIDO

2962.81.

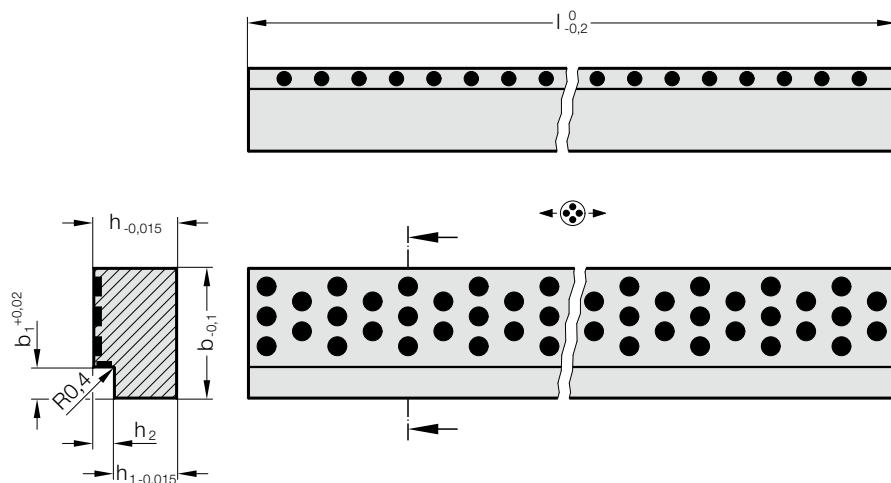

**Materiale:**

Bronzo con lubrificante solido, con esigenze di manutenzione ridotte

**2962.81. Elemento di scorrimento angolare, Bronzo con inserti di lubrificante solido**

N. d'ordine	h	b	l	h <sub>1</sub>	h <sub>2</sub>	b <sub>1</sub>
2962.81.016.115.040	16	11,5	40	12	4	6
2962.81.016.115.050	16	11,5	50	12	4	6
2962.81.016.115.063	16	11,5	63	12	4	6
2962.81.016.115.080	16	11,5	80	12	4	6
2962.81.016.155.050	16	15,5	50	11	5	8
2962.81.016.155.063	16	15,5	63	11	5	8
2962.81.016.155.080	16	15,5	80	11	5	8
2962.81.016.155.100	16	15,5	100	11	5	8
2962.81.020.195.063	20	19,5	63	15	5	8
2962.81.020.195.080	20	19,5	80	15	5	8
2962.81.020.195.100	20	19,5	100	15	5	8
2962.81.020.195.125	20	19,5	125	15	5	8
2962.81.020.245.080	20	24,5	80	15	5	8
2962.81.020.245.100	20	24,5	100	15	5	8
2962.81.020.245.125	20	24,5	125	15	5	8
2962.81.020.245.160	20	24,5	160	15	5	8
2962.81.025.315.100	25	31,5	100	19	6	10
2962.81.025.315.125	25	31,5	125	19	6	10
2962.81.025.315.160	25	31,5	160	19	6	10
2962.81.025.315.200	25	31,5	200	19	6	10
2962.81.025.395.125	25	39,5	125	19	6	10
2962.81.025.395.160	25	39,5	160	19	6	10
2962.81.025.395.200	25	39,5	200	19	6	10
2962.81.025.395.250	25	39,5	250	19	6	10
2962.81.032.495.160	32	49,5	160	24	8	12
2962.81.032.495.200	32	49,5	200	24	8	12
2962.81.032.495.250	32	49,5	250	24	8	12
2962.81.032.495.315	32	49,5	315	24	8	12