


SÜRTÜNME PLAKASI, ÇELİK, CNOMO




2962.84.45.




A

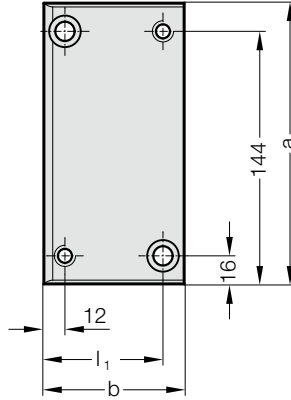

B

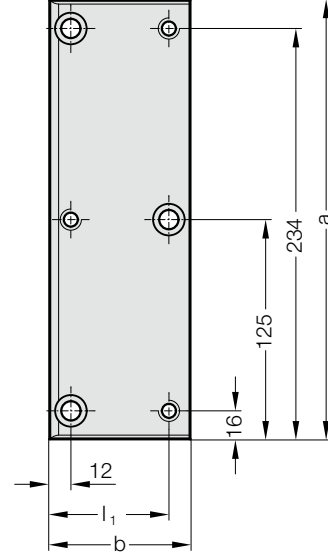

2962.84.45.

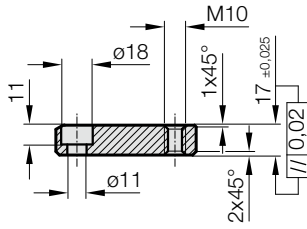

Malzeme:

Çelik, yüzeysel sertleştirilmiş

Not:

Civatalar dahil değildir.

Sabitleme:

Soket başlı vida kullanınız

DIN EN ISO 4762 M10.

2962.84.45. Sürtünme Plakası, Çelik, CNOMO

Sipariş No.	Şekil	b	a	l ₁	Vida havşası adedi	Vida dişi adedi
2962.84.45.050.17.160	A	50	160	38	2	2
2962.84.45.050.17.250	B	50	250	38	3	3
2962.84.45.080.17.160	A	80	160	68	2	2
2962.84.45.080.17.250	B	80	250	68	3	3