



SLIDING PAD, STEEL WITH SOLID LUBRICANT

2962.85.

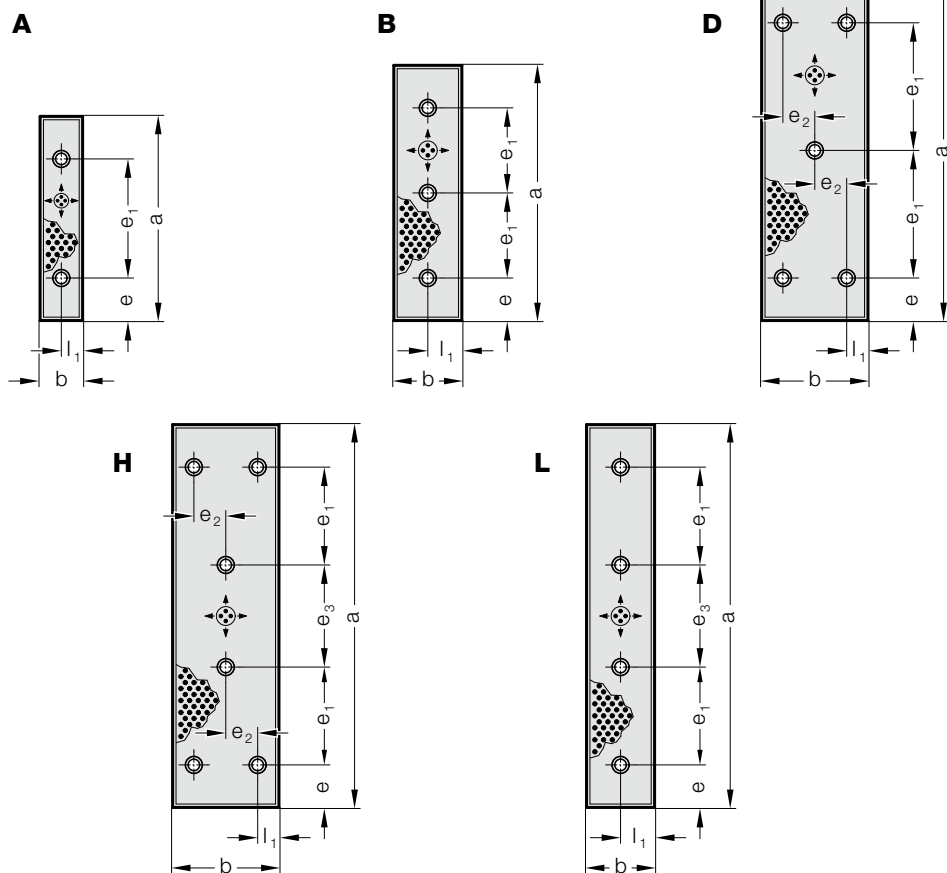

2962.85.

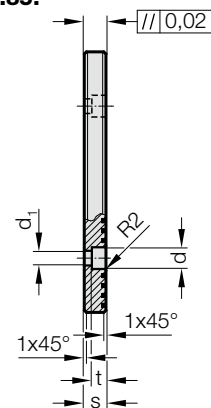

2962.85. Sliding pad, Steel with solid lubricant

Order No	Shape	b	s	a	l ₁	e	e ₁	e ₂	e ₃	Number of screw holes	d ₁	d	t
2962.85.050.20.240	A	50	20	240	25	50	140	-	-	2	13.5	20	13
2962.85.050.20.300	B	50	20	300	25	50	100	-	-	3	13.5	20	13
2962.85.050.20.350	B	50	20	350	25	50	125	-	-	3	13.5	20	13
2962.85.080.20.300	B	80	20	300	40	50	100	-	-	3	13.5	20	13
2962.85.080.20.350	B	80	20	350	40	50	125	-	-	3	13.5	20	13
2962.85.080.20.400	B	80	20	400	40	50	150	-	-	3	13.5	20	13
2962.85.080.20.450	L	80	20	450	40	50	115	-	120	4	13.5	20	13
2962.85.080.20.500	L	80	20	500	40	50	135	-	130	4	13.5	20	13
2962.85.125.20.400	D	125	20	400	25	50	150	37.5	-	5	13.5	20	13
2962.85.125.20.450	H	125	20	450	25	50	115	37.5	120	6	13.5	20	13
2962.85.125.20.500	H	125	20	500	25	50	135	37.5	130	6	13.5	20	13

Material:

Steel, surface hardened. Sliding faces with embedded solid lubricant.

Note:

Screws are not included.

Fixing:

Use socket cap screws
DIN EN ISO 4762 M12.