

Blindnietgewindebolzen RIFBOLT®



 
NEU Serie 10.885



ab Herbst 2014

Stahl

Flachkopf <
Sechsskantschaft <

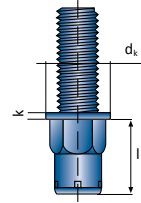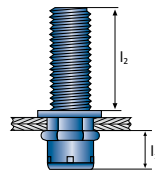

M	$\frac{+}{-}$	l	l ₂	Nr.	
M5	0,5 - 3,0	13,0	15	10.885.053.015	500
l ₁ max. 6,0 SW 7,0 d _k 10,0 k 1,0 10000N 6 Nm 9500N					
M6	0,5 - 3,0	14,0	20	10.885.063.020	500
l ₁ max. 7,0 SW 9,0 d _k 12,0 k 1,2 14000N 11Nm 12000N					

NEU

M	$\frac{+}{-}$	l	l ₂	Nr.	
M8	1,0 - 3,0	15,5	20	10.885.083.020	250
l ₁ max. 9,0 SW 11,0 d _k 15,0 k 1,5 24000N 27Nm 15000N					

NEU

l₂ = Min. Schraubenlänge in gesetztem Zustand.
Diese schwankt in Abhängigkeit von Klemmbereich und
Werkzeugeinstellung.