



drylin®-Disc, made from iglidur® J

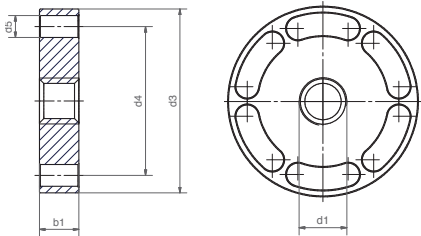

Order key

JDRM-4209TR10x2

 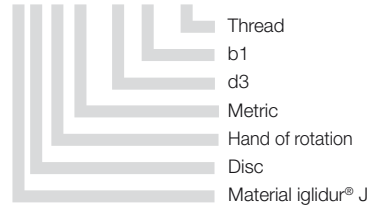


Dimensions [mm]

Part number	Effective supporting surface [mm²]	d3	d4	d5	b1	Thread	max. stat. F axial [N]
		h9				d1 x P	
JDRM-4209TR10x2	New! 127	42	34	5	9	TR10x2	508
JDRM-4811TR12x3	New! 181	48	38	6	11	TR12x3	724
JDRM-4811TR14x4	New! 207	48	38	6	11	TR14x4	828
JDRM-4811TR16x4	New! 241	48	38	6	11	TR16x4	964
JDRM-4811TR18x4	New! 276	48	38	6	11	TR18x4	1,104
JDRM-5513TR20x4	New! 367	55	45	7	13	TR20x4	1,468
JDRM-5513TR24x5	New! 439	55	45	7	13	TR24x5	1,756
JDRM-6214TR30x6	New! 551	62	50	7	13	TR30x6	2,204
JDRM-7016TR36x6	New! 829	70	58	7	16	TR36x6	3,316

* Max. stat. F axial can be added when used with flange nut

My Sketches



delivery from stock
time

prices price list online
www.igus.eu/eu/jdrm