



Lead screw nuts with spanner flat, made from iglidur® J, right-hand thread  
 iglidur® J – Best wear in dry operation

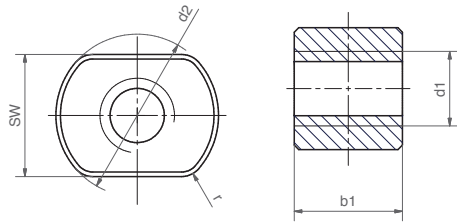

Order key

JSRM-172220TR10x2

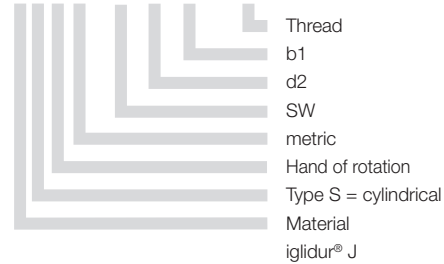


## Dimensions [mm]

Bestellnummer	Effective sup. surface [mm²]	SW	d2	b1	r	Thread d1 x P	max. stat. F axial [N]
JSRM-172220TR10x2	New! 282	17	22	20	3	TR10x2	1,128
JSRM-192624TR12x3	New! 394	19	26	24	3	TR12x3	1,576
JSRM-273624TR16x4	New! 526	27	36	24	5	TR16x4	2,108
JSRM-304540TR20x4	New! 1,130	30	45	40	6	TR20x4	4,520
JSRM-365048TR24x5	New! 1,620	36	50	48	8	TR24x5	6,480
JSRM-456060TR30x6	New! 2,542	45	60	60	10	TR30x6	10,168


Miniature lead screw nuts, made from iglidur® J, right-hand thread  
 iglidur® J – Best wear in dry operation

cylindrical

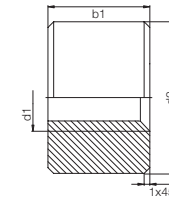

Order key


JSRM-1413M3

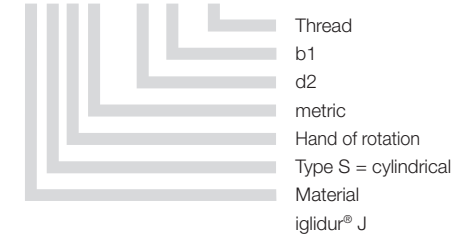

## Dimensions [mm]

Bestellnummer	Effective sup. surface [mm²]	d2	b1	Thread d1 x P	max. stat. F axial [N]
JSRM-1413M3	New! 56	14	13	M3x0.5	75
JSRM-1413M4	New! 74	14	13	M4x0.7	100
JSRM-1413M5	New! 91	14	13	M5x0.8	150
JSRM-1413M6	New! 112	14	13	M6x1	200

with flange

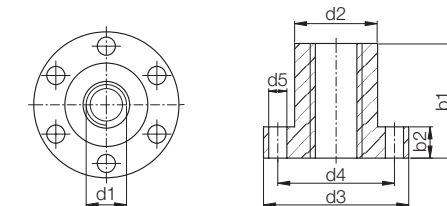

## Dimensions [mm]

Bestellnummer	Effective sup. surface [mm²]	d2	d3	d4	d5	b1	b2	Thread d1 x P	max. stat. F axial [N]
JFRM-0913M3	New! 56	9	18	15.2	3.2	13	3	M3x0.5	75
JFRM-0913M4	New! 74	9	18	15.2	3.2	13	3	M4x0.7	75
JFRM-0913M5	New! 91	9	18	15.2	3.2	13	3	M5x0.8	75
JFRM-1315M6	New! 129	13	25	19	3.2	15	5	M6x1	175