

- J** Hohe Geschwindigkeiten High speed
- W300** Hoch belastbar High load capacity
- J350** Temperaturen bis zu 150 °C
Temperatures up to 150 °C
- A180** FDA-konform FDA-compliant
- R** Günstig Low-cost

Bestellschlüssel
Order key

Typ Type	Abmessungen Dimensions	Gewinde Thread
DST- <input type="checkbox"/> S R M -	22 20	DS 10x2
dryspin® technology		
igidur® -Material wählen Choose igidur® material		
Form S= zylindrisch cylindric		
R = Rechtsgewinde right handed thread		
Metrisch metric		
Schlüsselfweite SW Wide across flats		
d2		
DS= dryspin® Steilgewinde High helix thread		
Ø		
Steigung Pitch		

Optionen Options:
R = Rechtsgewinde Right handed thread
L = Linksgewinde Left handed thread

- J** Hohe Geschwindigkeiten High speed
- W300** Hoch belastbar High load capacity
- J350** Temperaturen bis zu 150 °C
Temperatures up to 150 °C
- A180** FDA-konform FDA-compliant
- R** Günstig Low-cost

Bestellschlüssel
Order key


Typ Type	Abmessungen Dimensions	Gewinde Thread
DST- <input type="checkbox"/> F R M -	17 22 20	DS 10x2
dryspin® technology		
igidur® -Material wählen Choose igidur® material		
Form F= mit Flansch with flange		
R = Rechtsgewinde right handed thread		
Metrisch metric		
Schlüsselfweite SW Wide across flats		
d2		
b1		
DS= dryspin® Steilgewinde High helix thread		
Ø		
Steigung Pitch		

Optionen Options:
R = Rechtsgewinde Right handed thread
L = Linksgewinde Left handed thread

..dryspin® Steilgewinde... Vollsortiment ..

Abmessungen zylindrische Bauform Dimensions cylindrical version [mm]

Gewinde Thread d1 x P	d2	b1	Bestellnummer Part No. DST- <input type="checkbox"/> SR(L)M- ...
Ds6,35x2,54	14	13	...1413DS6.35X2.54
Ds6,35x5,08	14	13	...1413DS6.35X5.08
Ds6,35x12,7	14	13	...1413DS6.35X12.7
Ds6,35x25,4	14	13	...1413DS6.35X25.4
Ds10x12	22	20	...2220DS10X12
Ds10x25	22	20	...2220DS10X25
Ds10x50	22	20	...2220DS10X50
Ds14x25	30	27	...3027DS14X25
Ds14x30	30	27	...3027DS14X30
Ds16x35	36	32	...3632DS16X35
Ds18x40	40	36	...4036DS18X40
Ds18x80	40	36	...4036DS18X80
Ds20x60	45	40	...4540DS20X60
Ds20x90	45	40	...4540DS20X90

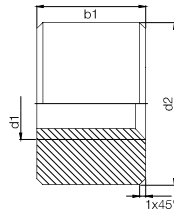

Abmessungen Bauform mit Flansch Dimensions flange version [mm]

Gewinde Thread d1 x P	d2	d3	d4	d5	b1	b2	SW	Bestellnummer Part No. DST- <input type="checkbox"/> FR(L)M- ...
Ds6.35x2.54	13	25	19	3,2	15	5	13	...131315DS6.35X2.54
Ds6.35x5.08	13	25	19	3,2	15	5	13	...131315DS6.35X5.08
Ds6.35x25.4	13	25	19	3,2	15	5	13	...131315DS6.35X25.4
Ds10x12	25	42	34	5	25	10	25	...252525DS10X12
Ds10x25	25	42	34	5	25	10	25	...252525DS10X25
Ds10x50	25	42	34	5	25	10	25	...252525DS10X50
Ds14x25	28	48	38	6	35	12	28	...282835DS14X25
Ds14x30	28	48	38	6	35	12	28	...282835DS14X30
Ds18x80	28	48	38	6	35	18	28	...282835DS18X80
Ds18x40	28	48	38	6	35	12	28	...282835DS18X40
Ds16x35	28	48	38	6	35	12	28	...282835DS16X35
Ds20x60	32	55	45	7	44	12	32	...323244DS20X60
Ds20x90	32	55	45	7	44	12	32	...323244DS20X90

