


High helix lead screws

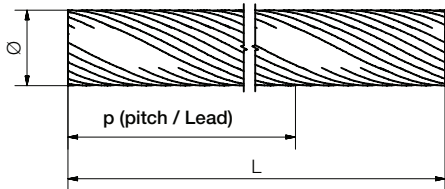

Order key

PTGSG-08x10-R-1000-ES



Material:
Stainless steel (1.4021)
Length
Hand of rotation
Lead
Diameter
Marking



Straightness 0,3 mm / 300 mm

High helix lead screws - Dimensions [mm]

Part number	Thread	Ø	Lead	Max. Length
PTGSG-05x5-R- <input type="text"/> **-ES	SG05x5	5.4	5	1,000
PTGSG-06.35x12.7-R- <input type="text"/> **-ES	SG06.35x12.7	6.4	12.7	1,000
PTGSG-08x10-R*- <input type="text"/> **-ES	SG08x10	8.2	10	2,000
PTGSG-08x15-R*- <input type="text"/> **-ES	SG08x15	8.0	15	2,000
PTGSG-10x12-R*- <input type="text"/> **-ES	SG10x12	10.0	12	2,000
PTGSG-10x50-R*- <input type="text"/> **-ES	SG10x50	10.0	50	2,000
PTGSG-12x25-R*- <input type="text"/> **-ES	SG12x25	11.9	25	2,000
PTGSG-18x24-R*- <input type="text"/> **-ES	SG18x24	18.7	24	2,000
PTGSG-18x100-R*- <input type="text"/> **-ES	SG18x100	18.8	100	2,000

* also available with left-hand thread „-L”, ** Length in mm



All drylin® leads screws can be custom machined. Please send us your drawing. We will submit an offer to you in a short time. We will also gladly offer metric lead screws, custom materials or more accurate versions.



delivery from stock
time



prices price list online
www.igus.eu/drylin-leadscrewdrives